


Cable Spool



CERTIFICATIONS

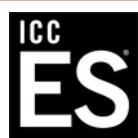

VLASTNOSTI

Cut to length as needed

Pre-stretched restraint cable

Certified chemically compatible with CPVC piping systems

Meets CEN/TS 17551:2021 requirements for Seismic Sway Bracing

SPECIFIKACE

Povrchová úprava: Pregalvanized; Painted

Materiál: Ocel

Table 1/1

Katalogové číslo	Article Number	Brace Size	Diameter	Cable Length	UL Listed Load	Barva
CSB12CBL	402190	#12	2.4 mm	76.2m	1859N	Red
CSB18CBL	402191	#18	3.2 mm	76.2m	3434N	White

Katalogové číslo	Article Number	Brace Size	Diameter	Cable Length	UL Listed Load	Barva
CSB36CBL	402192	#36	4.8 mm	76.2m	8490N	Blue

DALŠÍ PODROBNOSTI O PRODUKTU

Cable is powder coated.

FBC™ System Compatible indicates that this product has been tested, and is monitored on an ongoing basis, to assure its chemical compatibility with FlowGuard Gold®, BlazeMaster® and Corzan® piping systems and products made with TempRite® Technology.™ “The FBC System Compatible Logo, FBC™, FlowGuard Gold®, BlazeMaster®, Corzan®, and TempRite® are trademarks of Lubrizol Advanced Materials, Inc. or its affiliates.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

