

FleXbus HCBC Plate, 50 mm x 32 mm

Data Solutions

KATALOGOVÉ ČÍSLO

FLEXPLATE50



CERTIFICATIONS



VLASTNOSTI

Rigid tinned copper part provides strong electrical contact to maintain braid expansion during compression

HCBC Plate allows FleXbus Conductor insulation to overlap the connection palm

Tinned copper allows for copper or aluminum conductor connections

Installs quickly and easily

RoHS compliant

VLASTNOSTI PRODUKTU

Article Number: 508180

Materiál: Copper

Povrchová úprava: Tinned

A: 65mm

B: 63mm

C: 45mm

D: 41mm

Thickness (T): 5mm

Conductor Size: 220 mm²; 360 mm²; 545 mm²; 640 mm²


Unit Weight: 0.16kg

DALŠÍ PODROBNOSTI O PRODUKTU

It is mandatory to use the HCBC Clamp associated with the HCBC Plate for proper Flexbus Conductor connection.

It is mandatory to use the PIN associated with the HCBC Plate for proper connection mechanical resistance.

DIAGRAMS

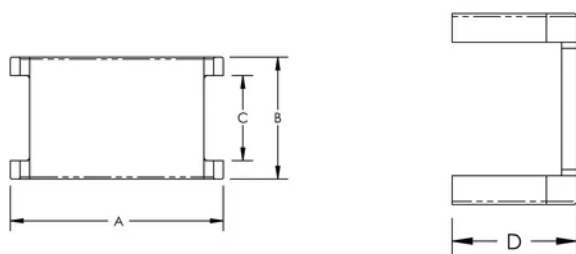

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte