


Four Pole Distrib. Block with Threaded Bars, 125 A

Data Solutions

KATALOGOVÉ ČÍSLO

TR-125A

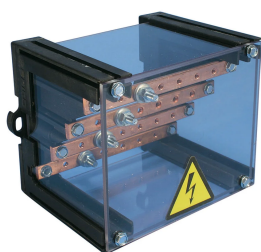

CERTIFICATIONS



VLASTNOSTI

Easily clips onto DIN rail or mounts to panel with screws

Equipped with a current input plug

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

VLASTNOSTI PRODUKTU

Article Number: 563150

Materiál: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 1000

Peak Short Circuit Current (Ipk): 40kA

Short Term Withstand Current (Icw) 1s: 8.4kA

Line Side Number of Connections: 1

Load Side Number of Connections: 5

Thread Size 1 (TS1): M5

Thread Size 2 (TS2): M6

Hloubka (D): 117mm

Height (H): 126mm

Width (W): 150mm

Unit Weight: 0.68kg

Flammability Rating: UL® 94V-0


Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

DALŠÍ PODROBNOSTI O PRODUKTU

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

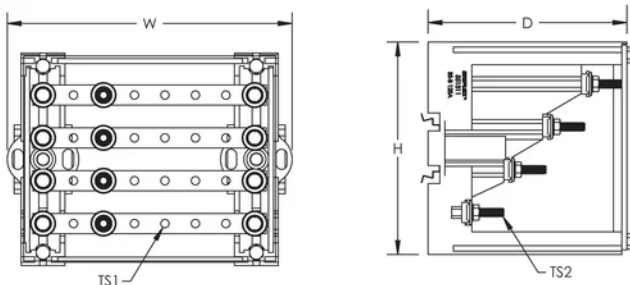

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE