


Four Pole Distrib. Block with Threaded Bars, 160 A

Data Solutions

KATALOGOVÉ ČÍSLO

TRS-160A

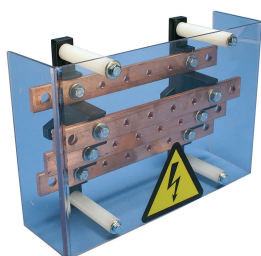

CERTIFICATIONS



VLASTNOSTI

Easily fixes onto asymmetric DIN rail or mounts with screws

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

VLASTNOSTI PRODUKTU

Article Number: 563160

Materiál: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 630

Peak Short Circuit Current (Ipk): 34kA

Short Term Withstand Current (Icw) 1s: 13.2kA

Line Side Number of Connections: 2

Load Side Number of Connections: 4

Hole Size (HS): 8mm

Thread Size (TS): M6

Hloubka (D): 68mm

Height (H): 150mm

Width (W): 230mm

Unit Weight: 1.15kg


Flammability Rating: UL® 94V-0

Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

DALŠÍ PODROBNOSTI O PRODUKTU

Line side and load side number of connections are per pole.

DIAGRAMS

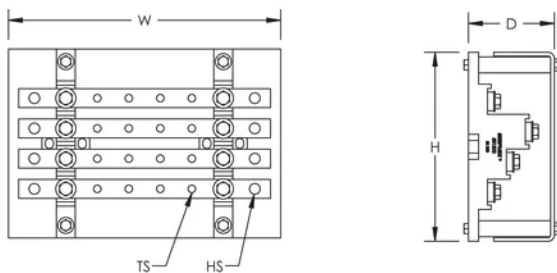

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE