

19" Front Panel

Front panels made of Aluminum.



CERTIFICATIONS



VLASTNOSTI

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

SPECIFIKACE

Rack Width:	95HP
Materiál:	Hliník
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Katalogové číslo	Rack Height	Hloubka (D)	Mounting	Povrchová úprava	Front Finish	Množství v balení
30118-948	1U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30118-299	1U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
40304-074	1U	4mm	Screw-on Front	Anodized	Anodized	1

Katalogové číslo	Rack Height	Hloubka (D)	Mounting	Povrchová úprava	Front Finish	Množství v balení
30219-098	1U	3mm	Screw-on Front	Anodized	Anodized	1
30118-954	7U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30118-955	8U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30118-953	6U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30118-305	6U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30118-952	5U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30219-113	6U	3mm	Screw-on Front	Anodized	Anodized	1
30219-104	3U	3mm	Screw-on Front	Anodized	Anodized	1
30118-949	2U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30118-303	4U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30118-309	10U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
40304-079	6U	4mm	Screw-on Front	Anodized	Anodized	1
30118-307	8U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
40304-077	4U	4mm	Screw-on Front	Anodized	Anodized	1
30118-304	5U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30118-306	7U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30118-301	2U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1

Table 2/2

Katalogové číslo	Rack Height	Hloubka (D)	Mounting	Povrchová úprava	Front Finish	Množství v balení
40304-076	3U	4mm	Screw-on Front	Anodized	Anodized	1
40304-082	9U	4mm	Screw-on Front	Anodized	Anodized	1
30219-137	7U	3mm	Screw-on Front	Anodized	Anodized	1
40304-080	7U	4mm	Screw-on Front	Anodized	Anodized	1
30219-143	9U	3mm	Screw-on Front	Anodized	Anodized	1

Katalogové číslo	Rack Height	Hloubka (D)	Mounting	Povrchová úprava	Front Finish	Množství v balení
30118-951	4U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30118-308	9U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30118-956	9U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30219-107	4U	3mm	Screw-on Front	Anodized	Anodized	1
30219-144	10U	3mm	Screw-on Front	Anodized	Anodized	1
40304-081	8U	4mm	Screw-on Front	Anodized	Anodized	1
30219-138	8U	3mm	Screw-on Front	Anodized	Anodized	1
30118-950	3U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30219-110	5U	3mm	Screw-on Front	Strukturovaný Práškový	Anodized	1
30118-302	3U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1
30219-101	2U	3mm	Screw-on Front	Anodized	Anodized	1
40304-083	10U	4mm	Screw-on Front	Anodized	Anodized	1
40304-075	2U	4mm	Screw-on Front	Anodized	Anodized	1
40304-078	5U	4mm	Screw-on Front	Anodized	Anodized	1
30118-957	10U	3mm	Screw-on Front	Strukturovaný Práškový	Painted	1

Table 1/2

Katalogové číslo	Rear Finish	Treated Edges	Kód barvy	EMC Shielding	Výška (H)	Typ
30118-948	Painted		RAL 7021	No	43.6mm	19" Front Panel
30118-299	Painted		RAL 7035	No	43.6mm	19" Front Panel
40304-074	Anodized	Yes		No	43.6mm	19" Front Panel
30219-098	Anodized	No		No	43.6mm	19" Front Panel
30118-954	Painted		RAL 7021	No	310.3mm	19" Front Panel
30118-955	Painted		RAL 7021	No	354.8mm	19" Front Panel
30118-953	Painted		RAL 7021	No	265.9mm	19" Front Panel
30118-305	Painted		RAL 7035	No	265.9mm	19" Front Panel
30118-952	Painted		RAL 7021	No	221.4mm	19" Front Panel
30219-113	Anodized	No		No	265.9mm	19" Front Panel
30219-104	Anodized	No		No	132.5mm	19" Front Panel

Katalogové číslo	Rear Finish	Treated Edges	Kód barvy	EMC Shielding	Výška (H)	Typ
30118-949	Painted		RAL 7021	No	88.1mm	19" Front Panel
30118-303	Painted		RAL 7035	No	177mm	19" Front Panel
30118-309	Painted		RAL 7035	No	443.7mm	19" Front Panel
40304-079	Anodized	Yes		No	265.9mm	19" Front Panel
30118-307	Painted		RAL 7035	No	354.8mm	19" Front Panel
40304-077	Anodized	Yes		No	177mm	19" Front Panel
30118-304	Painted		RAL 7035	No	221.4mm	19" Front Panel
30118-306	Painted		RAL 7035	No	310.3mm	19" Front Panel
30118-301	Painted		RAL 7035	No	88.1mm	19" Front Panel

Table 2/2

Katalogové číslo	Rear Finish	Treated Edges	Kód barvy	EMC Shielding	Výška (H)	Typ
40304-076	Anodized	Yes		No	132.5mm	19" Front Panel
40304-082	Anodized	Yes		No	399.2mm	19" Front Panel
30219-137	Anodized	No		No	310.3mm	19" Front Panel
40304-080	Anodized	Yes		No	310.3mm	19" Front Panel
30219-143	Anodized	No		No	399.2mm	19" Front Panel
30118-951	Painted		RAL 7021	No	177mm	19" Front Panel
30118-308	Painted		RAL 7035	No	399.2mm	19" Front Panel
30118-956	Painted		RAL 7021	No	399.2mm	19" Front Panel
30219-107	Anodized	No		No	177mm	19" Front Panel
30219-144	Anodized	No		No	443.7mm	19" Front Panel
40304-081	Anodized	Yes		No	354.8mm	19" Front Panel
30219-138	Anodized	No		No	354.8mm	19" Front Panel
30118-950	Painted		RAL 7021	No	132.5mm	19" Front Panel
30219-110	Anodized	No		No	221.4mm	19" Front Panel
30118-302	Painted		RAL 7035	No	132.5mm	19" Front Panel
30219-101	Anodized	No		No	88.1mm	19" Front Panel
40304-083	Anodized	Yes		No	443.7mm	19" Front Panel
40304-075	Anodized	Yes		No	88.1mm	19" Front Panel
40304-078	Anodized	Yes		No	221.4mm	19" Front Panel
30118-957	Painted		RAL 7021	No	443.7mm	19" Front Panel

Table 1/2

Katalogové číslo	Šířka (W)
30118-948	483mm
30118-299	483mm
40304-074	483mm
30219-098	483mm
30118-954	483mm
30118-955	483mm
30118-953	483mm
30118-305	483mm
30118-952	483mm
30219-113	483mm
30219-104	483mm
30118-949	483mm
30118-303	483mm
30118-309	483mm
40304-079	483mm
30118-307	483mm
40304-077	483mm
30118-304	483mm
30118-306	483mm
30118-301	483mm

Table 2/2


Katalogové číslo	Šířka (W)
40304-076	483mm
40304-082	483mm
30219-137	483mm
40304-080	483mm
30219-143	483mm
30118-951	483mm
30118-308	483mm
30118-956	483mm
30219-107	483mm
30219-144	483mm
40304-081	483mm
30219-138	483mm

Katalogové číslo	Šířka (W)
30118-950	483mm
30219-110	483mm
30118-302	483mm
30219-101	483mm
40304-083	483mm
40304-075	483mm
40304-078	483mm
30118-957	483mm

DALŠÍ PODROBNOSTI O PRODUKTU

Please order 19" assembly kit separately.

DIAGRAMS

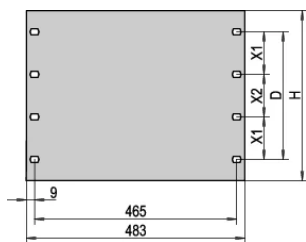

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE