

# AMC Front Panel With Pull Handle



AdvancedMC Front Panel including EMC gasket for AMC.0 Rev. 2.0 Modules.

## CERTIFICATIONS



## VLASTNOSTI

In accordance with AMC.0 R2.0 specification

Front panel for pull-handle mechanism (with cut-outs for light pipe)

For the use together with the AMC Pull-handle mechanism, AMC.0 R2.0

## SPECIFIKACE

**Accessory Type:** Front panel

**Product Type:** Front Panel

Table 1/2



Katalogové číslo	Výška (H)	Rack Width	Design Feature	Materiál	Povrchová úprava	Množství v balení
30849-658	73.8mm	4HP	Mid-Size	Hliník	Passivated	1
30849-694	148.8mm	6HP	Full-Size	Hliník	Passivated	1
30849-406	148.8mm	4HP	Mid-Size	Stainless Steel		1
30849-402	73.8mm	3HP	Compact	Stainless Steel		1
30849-403	73.8mm	4HP	Mid-Size	Stainless Steel		1

Katalogové číslo	Výška (H)	Rack Width	Design Feature	Materiál	Povrchová úprava	Množství v balení
30849-682	73.8mm	6HP	Full-Size	Hliník	Passivated	1
30849-407	148.8mm	6HP	Full-Size	Stainless Steel		1
30849-404	73.8mm	6HP	Full-Size	Stainless Steel		1
30849-670	148.8mm	4HP		Hliník	Passivated	1

Table 2/2

Katalogové číslo	Front Finish	Rear Finish	Hloubka (D)	Šířka (W)
30849-658	Raw	Raw	2.5mm	19mm
30849-694	Raw	Raw	2.5mm	29mm
30849-406	Raw	Raw	1mm	19mm
30849-402	Raw	Raw	1mm	13.9mm
30849-403	Raw	Raw	1mm	19mm
30849-682	Raw	Raw	2.5mm	29mm
30849-407	Raw	Raw	1mm	29mm
30849-404	Raw	Raw	1mm	29mm
30849-670	Raw	Raw	2.5mm	19mm

## DIAGRAMS

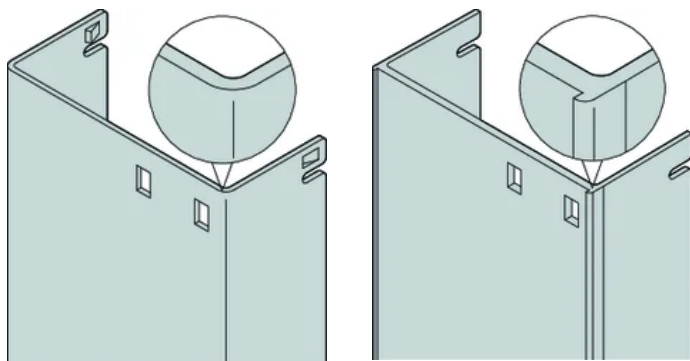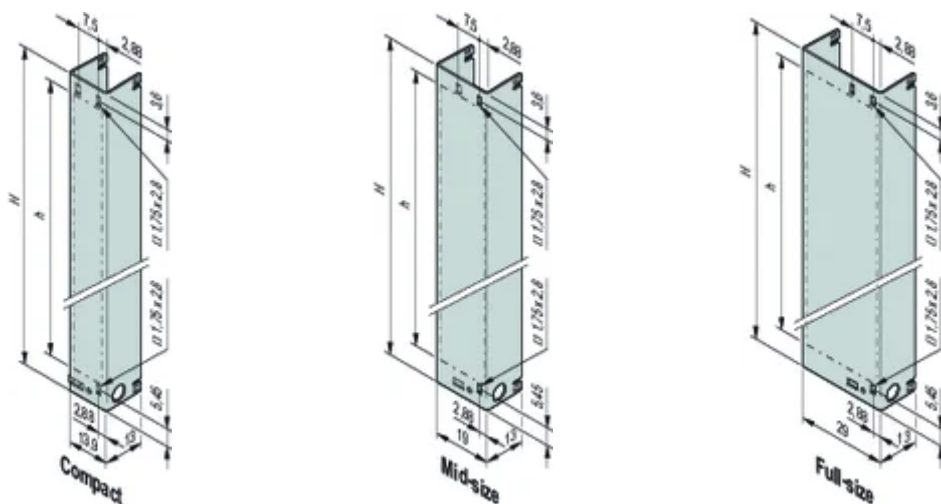

## UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Naše portfolio silných značek:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**