


Double Test Socket, Ø 2 mm

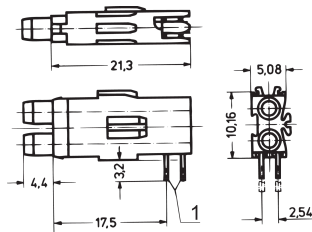

Double test sockets for mounting plane 1 and 2, short and long type.

Solder temperature should only be applied for a maximum of 5 seconds. The plastic body should be protected from the solder wave when wave soldering.

CERTIFICATIONS



VLASTNOSTI

Double test sockets for Front Element System

SPECIFIKACE

Diameter: 2mm
Product Type: Socket

Table 1/2

| Katalogové číslo | Typ | Množství v balení | Napětí střídavé | Maximální proud | Test Voltage @ 50 Hz | Okolní teplota |
|------------------|-------------------------|-------------------|-----------------|-----------------|----------------------|----------------|
| 69004-089 | Long, Mounting Plane 1 | 1 | 30V | 1A | 1kV | -25 to 70°C |
| 69004-131 | Short, Mounting Plane 1 | 1 | 30V | 1A | 1kV | -25 to 70°C |
| 69004-090 | Long, Mounting Plane 2 | 10 | 30V | 1A | 1kV | -25 to 70°C |

Table 2/2

| Katalogové číslo | Solder Temperature | Flammability Rating |
|------------------|--------------------|---------------------|
| 69004-089 | 260°C | UL® 94V-0 |

| Katalogové číslo | Solder Temperature | Flammability Rating |
|------------------|--------------------|---------------------|
| 69004-131 | 260°C | UL® 94V-0 |
| 69004-090 | 260°C | UL® 94V-0 |

DALŠÍ PODROBNOSTI O PRODUKTU

Dimensions of connecting pins: 0.3 × 0.6 mm.

Required front panel drill hole: Ø 4 mm.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE