


MTCA.0 System for 2 Single Full-Size AMC Modules, 1 HE

KATALOGOVÉ ČÍSLO

11850-023

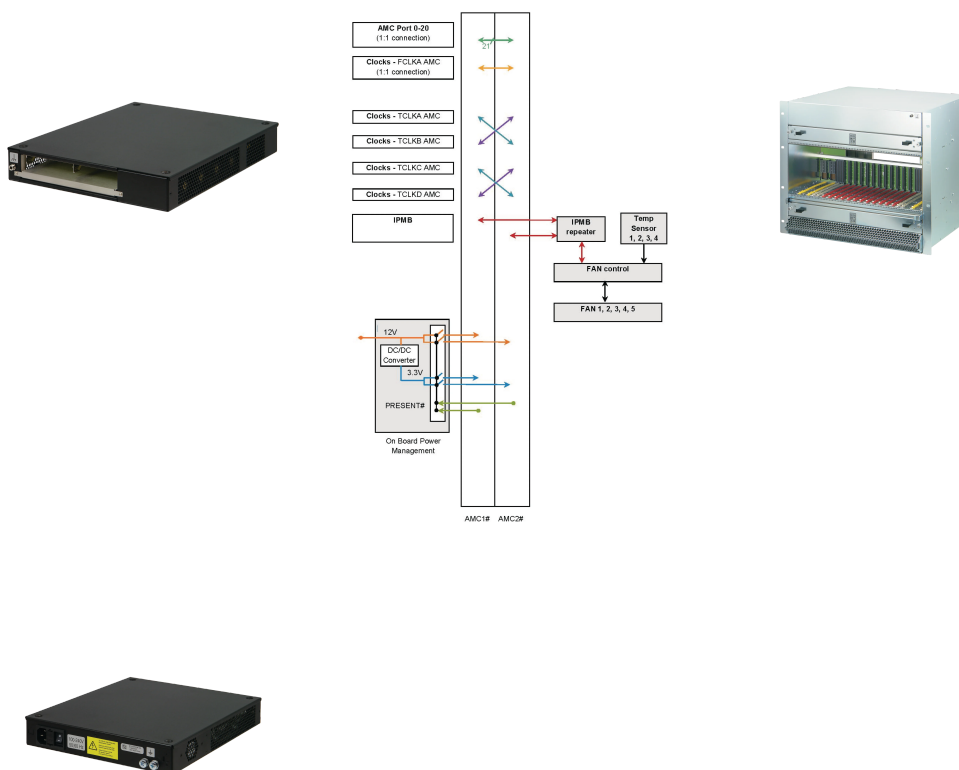

The System is designed for 2 AMC modules. The integrated Power Supply and Power switches on the backplane enable the Payload Power to the AMC Modules without the need for a separate MCH.

CERTIFICATIONS



VLASTNOSTI

Small, compact case to hold 2 single full-size AdvancedMC modules With an optional 2 HP filler module, 2 single mid-size modules can also be fitted

Direct connection of all ports between both AdvancedMC slots (see backplane topology); data transfer rates up to 10 Gbps per port

90 - 264 VAC wide range input on rear of case, 150 W power supply in rear section of enclosure

12 VDC voltage is activated by the AdvancedMC module presence signal

150 W cooling capacity at an ambient temperature of 55 °C, airflow from right to left, temperature-regulated fans

Fan unit and fan filter are easy to service or replace

The enclosure is stackable and prepared for plate mounting

VLASTNOSTI PRODUKTU

Product Type: System

Number of Slots: 2

Typ: Pico System

Backplane Type: All Ports Point to Point Connected

Data Transfer: 40 GbE; PCIe Gen3

Power per Slot: 60W

Vstupní napětí AC: 100 – 240V

Airflow Direction: Right to Left

Rack Height: 1U

Power Supply Type: Open Frame

Power Supply Included: Yes

Rear I/O: No

Complies With: PICMG MTCA.0 R2.0

Hloubka: 302mm

Množství v balení: 1

DALŠÍ PODROBNOSTI O PRODUKTU

Modified systems available on request.

Completely assembled, wired and tested.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE