


# PropacPRO Front Panel, Full Width, Unshielded

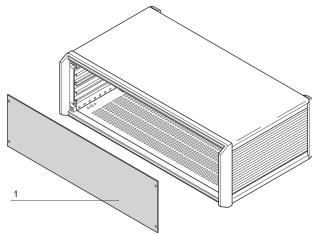

The front panel, full width for PropacPRO Case mounts to the frame of the case.

## CERTIFICATIONS



## VLASTNOSTI

Al panel, 2.0 mm (84 HP 2.5 mm)

## SPECIFIKACE

<b>Materiál:</b>	Hliník
<b>Povrchová úprava:</b>	Anodized
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel

Table 1/2

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Front Finish	Rear Finish	Treated Edges
20850-136	3U	63HP	1	Anodized	Anodized	No
20850-158	6U	84HP	1	Anodized	Conductive	No
20850-129	2U	63HP	1	Anodized	Anodized	No
20850-135	3U	42HP	1	Anodized	Anodized	No
20850-142	4U	42HP	1	Anodized	Anodized	No
20850-143	4U	63HP	1	Anodized	Anodized	No
20850-130	2U	84HP	1	Anodized	Anodized	No

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Front Finish	Rear Finish	Treated Edges
20850-144	4U	84HP	1	Anodized	Anodized	No
20850-134	3U	28HP	1	Anodized	Anodized	No
20850-128	2U	42HP	1	Anodized	Anodized	No
20850-137	3U	84HP	1	Anodized	Anodized	No

Table 2/2

Katalogové číslo	Hloubka	Výška	Šířka
20850-136	2mm	128.5mm	345.4mm
20850-158	2.5mm	261.8mm	452mm
20850-129	2mm	84mm	345.4mm
20850-135	2mm	128.5mm	238.7mm
20850-142	2mm	172.9mm	238.7mm
20850-143	2mm	172.9mm	345.4mm
20850-130	2.5mm	84mm	452mm
20850-144	2.5mm	172.9mm	452mm
20850-134	2mm	128.5mm	167.6mm
20850-128	2mm	84mm	238.7mm
20850-137	2.5mm	128.5mm	452mm

## UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Naše portfolio silných značek:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**