

# MTSH Spring Toggle with Hook



## FUNKTIONER

For fixing into hollow walls, hollow ceilings and suspended ceilings

Washer, nut and toggle included

## SPECIFIKATIONER

Table 1/2

| Katalognummer | Artikelnummer | Materiale | Finish            | Rod Size (RS) | Length (L) | Drill Bit Diameter |
|---------------|---------------|-----------|-------------------|---------------|------------|--------------------|
| MTSH4         | 584430        | Stål      | Electrogalvanized | 4             | 70mm       | 14mm               |

Table 2/2


| Katalognummer | Artikelnummer | Ultimate Static Load (F) |
|---------------|---------------|--------------------------|
| MTSH4         | 584430        | 300N                     |

## YDERLIGERE PRODUKTOPLYSNINGER

The Ultimate Static Load value does not take into account the load-bearing characteristics of the supporting material. The appropriate safety factor is to be added to this load rating.

Spring toggle requires a minimum clearance of 35 mm (1.38") to open when installed.

## DIAGRAMS

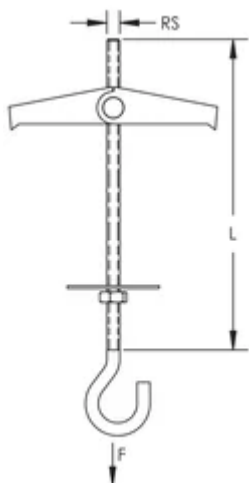

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

