

Low Voltage Insulators, Metric Thread, 50 mm, 50 mm Hex Width, M12 Thread

Data Solutions

KATALOGNUMMER

ISOTP50M12



CERTIFICERINGER



FUNKTIONER

Halogen free

High resistance to leakage current

Great stability of electrical and mechanical parameters

Fiberglass reinforced

UL® Recognized in E125470 and evaluated for dielectric withstand rating of 1,500 VAC/DC

RoHS compliant

PRODUKTEGENSKABER

Artikelnummer: 548581

Materiale: Stål; Glass Fibre Reinforced Polyamide

Finish: Electrogalvanized

Working Temperature: -40 to 130°C

Flammability Rating: UL® 94V-0

Complies With: IEC® 60695-2-11 (Glow Wire Test 960 °C)

Dielectric Strength, IEC 61439.1: 3500 VAC @ 1 min

Dielectric Strength, UL: 1500

Insulation Voltage: 1000; 1500

Height (H): 50mm

Hex Width (W): 50mm

Dybde (D): 57mm

Thread Size (TS): M12

Thread Depth (TD): 14.5mm

Diameter (Ø): 41mm

Static Load 1 (F1): 2000daN


Static Load 2 (F2): 1000daN

Unit Weight: 0.19kg

YDERLIGERE PRODUKTOPLYSNINGER

Creepage and clearance distances need to be in accordance with the relevant application standard.

DIAGRAMS

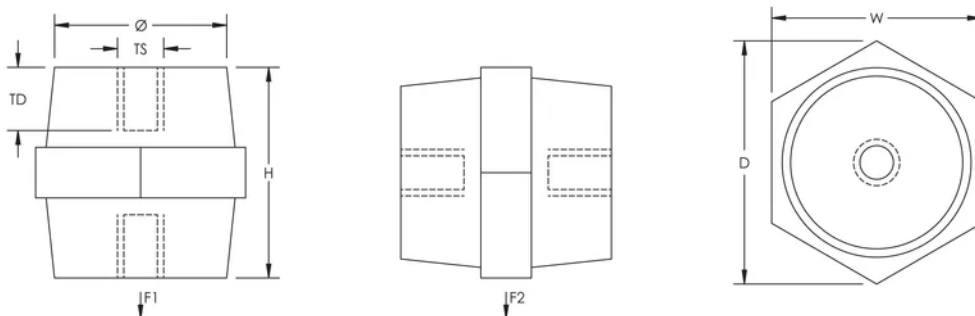

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer.

Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE