


Door Contact Switch Without Cable

Data Solutions

KATALOGNUMMER

20118-810

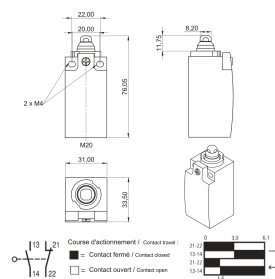

Door contact switch with magnetic contact, allows operational efficiency. This product is easy handlable by plug and play.

CERTIFICERINGER



FUNKTIONER

Door contact switch (without connection cable)

PRODUKTEGENSKABER

Product Type: Switch

Dybde: 33.5mm

Højde: 76.5mm

Driftstemperatur: -25 to 75°C

Beskyttelsesgrad: IP66

Bredde: 31mm

Complies With: UL® 508; EN 50047 form B

Current Rating: 3 – 6A

Gross Weight: 0.1kg

Pakke mængde: 1

Voltage: 24 – 230V

Trådstørrelse: 0.5 – 2.5mm²

YDERLIGERE PRODUKTOPLYSNINGER

Please order bracket for installation of door switch (Varistar, Novastar, Eurorack) separately.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE