


# Varistar CP Steel Door, Perforated With 1-Point Locking, Key Plate Only, RAL 7021, 24 U, 1200H 600W

## Data Solutions

### KATALOGNUMMER

---

**21630-507**

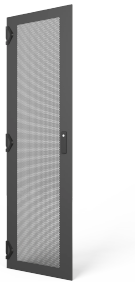

Varistar CP Perforated Steel Door, IP 20 with Single Point Locking.

### FUNKTIONER

---

Perforated steel door with single point locking for IP 20 protection class

Opening angle 180°

Key lock cover

### PRODUKTEGENSKABER

---

Rack Height: 24U

Højde: 1200mm

Bredde: 600mm

Locking Type: Single Point Locking

Pakke mængde: 1

Farve: Black Grey

Farvekode: RAL 7021

Complies With: IEC 61587-1

Materiale: Stål

Produktfamilie: Varistar CP

Product Type: Cabinet Door

Beskyttelsesgrad: IP20

Type: Steel Door, Perforated

Works With: Varistar CP

Net Weight: 9.022kg

## YDERLIGERE PRODUKTOPLYSNINGER

---

24U - 33U IP20 doors have 2 hinges, 38U - 52U IP20 doors have 3 hinges to ensure robust IP20 closing structures for taller cabinets

Please order lever handle 24630003 and the DIN lock separately if you want to replace the 1333 DIN lock lever handle

Please purchase the grounding kit separately.

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer.

Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**