


Male and Female Connection with Terminal Block for AC Lamp

Data Solutions

KATALOGNUMMER

57274

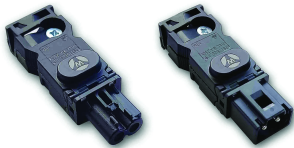

The enclosure light provides a compact and flexible solution, and offers fast, easy assembly and installation. For mounting flexibility, the LED light can be fastened to the enclosure with screws or quickly attached to any flat steel surfaces with optional magnetic kits. A motion sensor is also available.

CERTIFICERINGER



FUNKTIONER

Power cable for LED light mounting into cabinet

Lights can be easily mounted vertically or horizontally

Simple through-wiring based on a plug-and-play system

PRODUKTEGENSKABER

Indgangsspænding AC: 250V max

Accessory Type: Lights

Beskyttelsesgrad: IP20

Pakke mængde: 1

Farve: Black

Dybde: 14mm

Finish: Smooth Matte

Højde: 53mm

Materiale: Plastik

Product Type: Light

Type: Cabinet Light; Terminal Block

Bredde: 18mm

Tilslutningstype: Infeed; Trough-Wiring; 2-Pole

Nominel spænding: 250V

Driftstemperatur: 60°C min

Rated Current: 16A

Vægt: 0.07kg

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE