


MS PDU, 2U, 60A(48A)NA/60A Int, 380-415V, 3P Wye, 9 CB, (9)C13, (9)4-in-1

Data Solutions

KATALOGNUMMER

EN2954

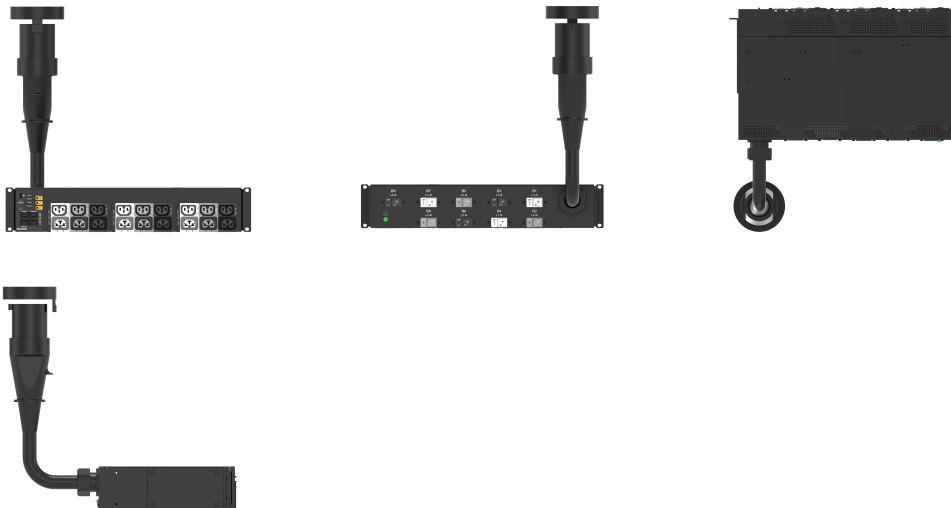

The Advantage Series Input Metered, Outlet Switched PDU family offers energy metering with advanced power and environmental monitoring options and remote outlet on/off switching. Comprehensive monitoring at both the input phase and circuit breaker levels offers advanced alerts of potential overloads. Billing-grade metering provides accurate power consumption data for energy use optimization. The hot-swappable network management controller features Gigabit and redundant ethernet communication with advanced support for external environmental sensors and rack security access solutions.

PRODUKTEGENSKABER

Produktfamilie: Enlogic

Product Type: Socket Strip

Stiktype: (9) C13/C15; (9) C13/C15/C19/C21

Farve: Black

Circuit Breaker: 20 A

Switched Outlets: Yes

Circuit Breaker Quantity: 9

Length: 87mm

Power Rating: 34.6 kVA North America; 41.4 kVA International

Number of Poles: 1

Input Voltage: 380 – 415V

Phase: 3 PH

Output Voltage: 208 – 230VAC

Plug Type: IEC 60309 560P6 (IP44)

Nominal spænding: 415V

Removable Input Cable: No

Amperage (Derated Amperage): 60 A (48 A) North America; 60 A International

Rack Units: 2U

Type: Intelligent PDU

Finish: Struktur Pulvermaling

Materiale: Stål

Højde: 87mm

Bredde: 444mm

Dybde: 269mm

Vægt: 9kg

Pakke mængde: 1

Input Cable Length: 1.8m

YDERLIGERE PRODUKTOPLYSNINGER

87 mm L x 444 mm W x 269 mm D, (269 mm D at CB)

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE