


TR Four Pole Distribution Block, 125 A

Data Solutions

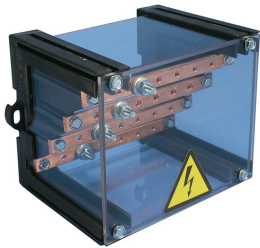

CERTIFICERINGER



FUNKTIONER

Easily clips onto DIN rail or mounts to panel with screws

Equipped with a current input plug

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

SPECIFIKATIONER

Katalognummer	TR-125A
Artikelnummer	563150
Materiale	Copper Glass Fibre Reinforced Polyamide Plexiglass


Katalognummer	TR-125A
Max Working Voltage, IEC (Ui)	1000
Peak Short Circuit Current (Ipk)	40kA
Short Term Withstand Current (Icw) 1s	8.4kA
Line Side Number of Connections	1
Load Side Number of Connections	5
Thread Size 1 (TS1)	M5
Thread Size 2 (TS2)	M6
Dybde (D)	117mm
Height (H)	126mm
Width (W)	150mm
Unit Weight	0.68kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

YDERLIGERE PRODUKTOPLYSNINGER

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

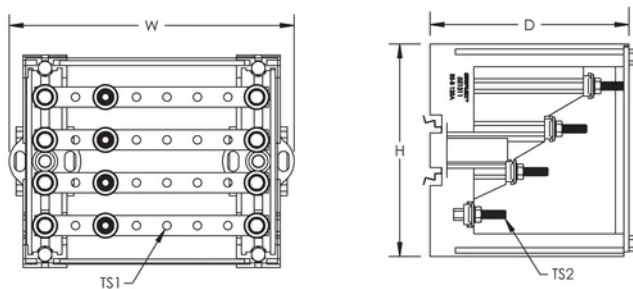

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unndladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE