

# TRC Four Pole Distribution Block, 400 A

## Data Solutions



### CERTIFICERINGER



### FUNKTIONER

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

### SPECIFIKATIONER

Table 1/2	
<b>Katalognummer</b>	<b>TRC-400A</b>
Artikelnummer	563180
Materiale	Copper Glass Fibre Reinforced Polyamide Plexiglass

<b>Katalognummer</b>	<b>TRC-400A</b>
Max Working Voltage, IEC (Ui)	1000
Peak Short Circuit Current (Ipk)	118kA
Short Term Withstand Current (Icw) 1s	28kA
Line Side Number of Connections	1
Load Side Number of Connections	10
Thread Size 1 (TS1)	M6
Thread Size 2 (TS2)	M10
Dybde (D)	50mm
Height (H)	338 – 390mm
Width (W)	260mm
A	290mm
Unit Weight	2.65kg
Flammability Rating	UL® 94V-0

Table 2/2


<b>Katalognummer</b>	<b>TRC-400A</b>
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

## YDERLIGERE PRODUKTOPLYSNINGER

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

## DIAGRAMS

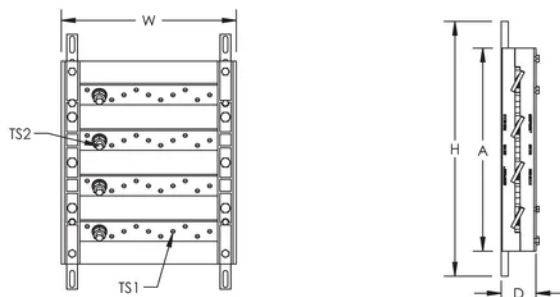

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl,

materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**