

B162 Earthpoint, Two Stud



FUNKTIONER

Long-lasting design

Low ground resistance and impedance

Superior electrical conductivity and resistance to corrosion

Electrically and mechanically robust and reliable

Easy to install as a Prefabricated Earthbridge once nVent ERICO Cadweld welded to a piece of conductor

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Materiale	Width 1 (W1)	Width 2 (W2)	Dybde (D)	Height (H)
B16212A	166210	Copper	44.5 mm	85 mm	45mm	76.2 mm
B1622Q		Brass	44.45 mm	82.55 mm	41.28mm	76.2 mm


Table 2/2

Katalognummer	Artikelnummer	Diameter (Ø)	Thread Size (TS)
B16212A	166210	10.7 mm	M12
B1622Q		13.46 mm	1/2" UNC

YDERLIGERE PRODUKTOPLYSNINGER

Assemblies require conductors and nVent ERICO Cadweld connections, which must be ordered separately.

DIAGRAMS

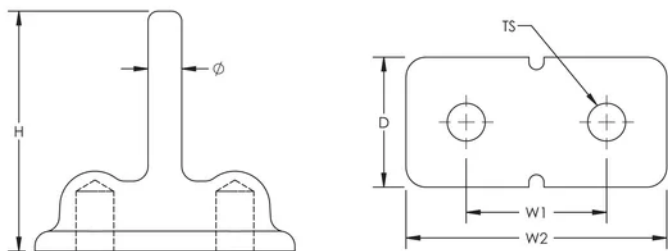

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE