


# Solid Copper Ground Rod, Sectional Internal Thread

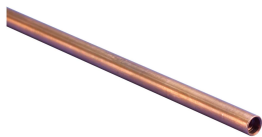

## FUNKTIONER

Solid copper sectional ground rod with internal threading

## SPECIFIKATIONER

**Tensile Strength:** 50 MPa

**Materiale:** Copper


Table 1/1

| Katalognummer | Artikelnummer | Ground Rod Diameter, Actual (Ø) | Thread Size (TS) | Length (L) | Unit Weight |
|---------------|---------------|---------------------------------|------------------|------------|-------------|
| SCR15         | 710070        | 15 mm                           | M10              | 1.2m       | 1.64 kg     |
| SCR20         | 710080        | 20 mm                           | M10              | 1.2m       | 3.34 kg     |

## YDERLIGERE PRODUKTOPLYSNINGER

Due to the inherent softness of the copper material, special consideration should be given when driving this product into the soil.

## DIAGRAMS

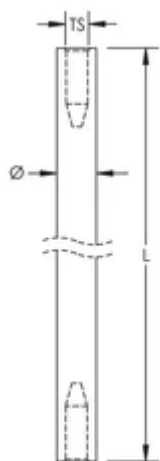

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**