

BS-400A Four Pole Insulating Support



CERTIFICERINGER



FUNKTIONER

Create custom four pole distribution blocks for an electrical distribution system

Protection screen can be attached directly to the support

Includes screws to mount threaded copper busbars

Easily clips onto DIN rail or mounts to panel with screws

Halogen free

RoHS compliant

SPECIFIKATIONER

Table 1/3

| Katalognummer | Artikelnummer | Materiale | Finish | Max Working Voltage, IEC (Ui) | Working Temperature | Typical Application Current Rating |
|---------------|---------------|--|-------------------|-------------------------------|---------------------|------------------------------------|
| BS-400A | 551250 | Stål, Glass Fibre Reinforced Polyamide | Electrogalvanized | 1000, 1500 | -40 to 130 °C | 160 - 630 A |

Table 2/3

| Katalognummer | Artikelnummer | Complies With | Flammability Rating | Busbar Width | Busbar Thickness | Dybde (D) |
|---------------|---------------|---|---------------------|--------------|------------------|-----------|
| BS-400A | 551250 | IEC® 60439.1, IEC® 61439.1, IEC® 60695-2-11 (Glow Wire Test 960 °C) | UL® 94V-0 | 15 - 32 mm | 5 - 10 mm | 128mm |


Table 3/3

| Katalognummer | Artikelnummer | Height (H) | Width (W) | A | Screw Diameter (Sc) | Unit Weight |
|---------------|---------------|------------|-----------|--------|---------------------|-------------|
| BS-400A | 551250 | 230 mm | 34 mm | 123 mm | 6 | 0.22 kg |

YDERLIGERE PRODUKTOPLYSNINGER

Must be used with copper busbars.

DIAGRAMS

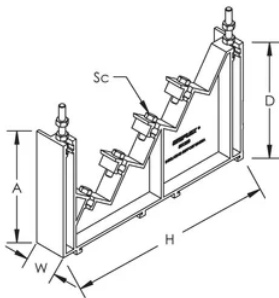

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE