


19" Front Panel, Vented

Vented front panels allows heat dissipation through holes.

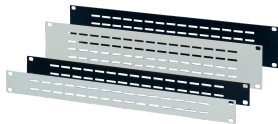

CERTIFICERINGER



FUNKTIONER

Vented front panels (Aluminum) allows heat dissipation

SPECIFIKATIONER

Rack Width:	95HP
Materiale:	Aluminium
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Katalognummer	Rack Height	Finish	Mounting	Pakke mængde	Front Finish	Rear Finish
30118-962	1U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30702-047	1U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-056	1U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30702-044	1U	Anodized	Screw-on Front	1	Raw	Conductive


Katalognummer	Rack Height	Finish	Mounting	Pakke mængde	Front Finish	Rear Finish
30118-963	2U	Anodized	Screw-on Front	1	Painted	Painted
30702-048	2U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-057	2U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30118-964	3U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30702-058	3U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30702-046	3U	Anodized	Screw-on Front	1	Raw	Raw
30702-045	2U	Anodized	Screw-on Front	1	Raw	Raw
30702-049	3U	Anodized	Screw-on Front	1	Anodized	Anodized

Table 2/2						
Katalognummer	Treated Edges	Farvekode	EMC Shielding	Højde (H)	Type	Bredde (W)
30118-962		RAL 7021	No	43.6mm	19" Front Panel	483mm
30702-047	Yes		No	43.6mm	19" Front Panel	483mm
30702-056		RAL 7035	No	43.6mm	19" Front Panel	483mm
30702-044			No	43.6mm	19" Front Panel	483mm
30118-963		RAL 7021	No	88.1mm	19" Front Panel	483mm
30702-048	Yes		No	88.1mm	19" Front Panel	483mm
30702-057		RAL 7035	No	88.1mm	19" Front Panel	483mm
30118-964		RAL 7021	No	132.5mm	19" Front Panel	483mm
30702-058		RAL 7035	No	132.5mm	19" Front Panel	483mm
30702-046			No	132.5mm	19" Front Panel	483mm
30702-045			No	88.1mm	19" Front Panel	483mm
30702-049	Yes		No	132.5mm	19" Front Panel	483mm

YDERLIGERE PRODUKTOPLYSNINGER

Please order 19" assembly kit separately.

DIAGRAMS

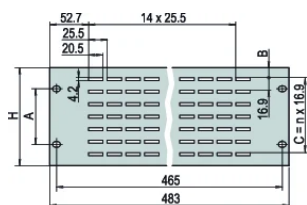

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE