

19" Front Panel

Front panels made of Aluminum.



CERTIFICERINGER



FUNKTIONER

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

SPECIFIKATIONER

Rack Width:	95HP
Materiale:	Aluminium
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/3

Katalognummer	Rack Height	Dybde (D)	Mounting	Finish	Front Finish	Pakke mængde
30118-948	1U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30118-299	1U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
40304-074	1U	4mm	Screw-on Front	Anodized	Anodized	1
30219-098	1U	3mm	Screw-on Front	Anodized	Anodized	1

Katalognummer	Rack Height	Dybde (D)	Mounting	Finish	Front Finish	Pakke mængde
30118-954	7U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30118-955	8U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30118-953	6U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30118-305	6U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30118-952	5U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30219-113	6U	3mm	Screw-on Front	Anodized	Anodized	1
30219-104	3U	3mm	Screw-on Front	Anodized	Anodized	1
30118-949	2U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30118-303	4U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30118-309	10U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
40304-079	6U	4mm	Screw-on Front	Anodized	Anodized	1
30118-307	8U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
40304-077	4U	4mm	Screw-on Front	Anodized	Anodized	1
30118-304	5U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30118-306	7U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30118-301	2U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
40304-076	3U	4mm	Screw-on Front	Anodized	Anodized	1
40304-082	9U	4mm	Screw-on Front	Anodized	Anodized	1
30219-137	7U	3mm	Screw-on Front	Anodized	Anodized	1
40304-080	7U	4mm	Screw-on Front	Anodized	Anodized	1
30219-143	9U	3mm	Screw-on Front	Anodized	Anodized	1
30118-951	4U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30118-308	9U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30118-956	9U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1

Katalognummer	Rack Height	Dybde (D)	Mounting	Finish	Front Finish	Pakke mængde
30219-107	4U	3mm	Screw-on Front	Anodized	Anodized	1
30219-144	10U	3mm	Screw-on Front	Anodized	Anodized	1
40304-081	8U	4mm	Screw-on Front	Anodized	Anodized	1
30219-138	8U	3mm	Screw-on Front	Anodized	Anodized	1
30118-950	3U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30219-110	5U	3mm	Screw-on Front	Struktur Pulvermaling	Anodized	1
30118-302	3U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1
30219-101	2U	3mm	Screw-on Front	Anodized	Anodized	1
40304-083	10U	4mm	Screw-on Front	Anodized	Anodized	1
40304-075	2U	4mm	Screw-on Front	Anodized	Anodized	1
40304-078	5U	4mm	Screw-on Front	Anodized	Anodized	1
30118-957	10U	3mm	Screw-on Front	Struktur Pulvermaling	Painted	1

Table 2/3

Katalognummer	Rear Finish	Treated Edges	Farvekode	EMC Shielding	Højde (H)	Type
30118-948	Painted		RAL 7021	No	43.6mm	19" Front Panel
30118-299	Painted		RAL 7035	No	43.6mm	19" Front Panel
40304-074	Anodized	Yes		No	43.6mm	19" Front Panel
30219-098	Anodized	No		No	43.6mm	19" Front Panel
30118-954	Painted		RAL 7021	No	310.3mm	19" Front Panel
30118-955	Painted		RAL 7021	No	354.8mm	19" Front Panel
30118-953	Painted		RAL 7021	No	265.9mm	19" Front Panel
30118-305	Painted		RAL 7035	No	265.9mm	19" Front Panel
30118-952	Painted		RAL 7021	No	221.4mm	19" Front Panel
30219-113	Anodized	No		No	265.9mm	19" Front Panel
30219-104	Anodized	No		No	132.5mm	19" Front Panel
30118-949	Painted		RAL 7021	No	88.1mm	19" Front Panel
30118-303	Painted		RAL 7035	No	177mm	19" Front Panel
30118-309	Painted		RAL 7035	No	443.7mm	19" Front Panel
40304-079	Anodized	Yes		No	265.9mm	19" Front Panel
30118-307	Painted		RAL 7035	No	354.8mm	19" Front Panel

Katalognummer	Rear Finish	Treated Edges	Farvekode	EMC Shielding	Højde (H)	Type
40304-077	Anodized	Yes		No	177mm	19" Front Panel
30118-304	Painted		RAL 7035	No	221.4mm	19" Front Panel
30118-306	Painted		RAL 7035	No	310.3mm	19" Front Panel
30118-301	Painted		RAL 7035	No	88.1mm	19" Front Panel
40304-076	Anodized	Yes		No	132.5mm	19" Front Panel
40304-082	Anodized	Yes		No	399.2mm	19" Front Panel
30219-137	Anodized	No		No	310.3mm	19" Front Panel
40304-080	Anodized	Yes		No	310.3mm	19" Front Panel
30219-143	Anodized	No		No	399.2mm	19" Front Panel
30118-951	Painted		RAL 7021	No	177mm	19" Front Panel
30118-308	Painted		RAL 7035	No	399.2mm	19" Front Panel
30118-956	Painted		RAL 7021	No	399.2mm	19" Front Panel
30219-107	Anodized	No		No	177mm	19" Front Panel
30219-144	Anodized	No		No	443.7mm	19" Front Panel
40304-081	Anodized	Yes		No	354.8mm	19" Front Panel
30219-138	Anodized	No		No	354.8mm	19" Front Panel
30118-950	Painted		RAL 7021	No	132.5mm	19" Front Panel
30219-110	Anodized	No		No	221.4mm	19" Front Panel
30118-302	Painted		RAL 7035	No	132.5mm	19" Front Panel
30219-101	Anodized	No		No	88.1mm	19" Front Panel
40304-083	Anodized	Yes		No	443.7mm	19" Front Panel
40304-075	Anodized	Yes		No	88.1mm	19" Front Panel
40304-078	Anodized	Yes		No	221.4mm	19" Front Panel
30118-957	Painted		RAL 7021	No	443.7mm	19" Front Panel

Table 3/3


Katalognummer	Bredde (W)
30118-948	483mm
30118-299	483mm
40304-074	483mm
30219-098	483mm
30118-954	483mm
30118-955	483mm
30118-953	483mm
30118-305	483mm

Katalognummer	Bredde (W)
30118-952	483mm
30219-113	483mm
30219-104	483mm
30118-949	483mm
30118-303	483mm
30118-309	483mm
40304-079	483mm
30118-307	483mm
40304-077	483mm
30118-304	483mm
30118-306	483mm
30118-301	483mm
40304-076	483mm
40304-082	483mm
30219-137	483mm
40304-080	483mm
30219-143	483mm
30118-951	483mm
30118-308	483mm
30118-956	483mm
30219-107	483mm
30219-144	483mm
40304-081	483mm
30219-138	483mm
30118-950	483mm
30219-110	483mm
30118-302	483mm
30219-101	483mm
40304-083	483mm
40304-075	483mm
40304-078	483mm
30118-957	483mm

YDERLIGERE PRODUKTOPLYSNINGER

Please order 19" assembly kit separately.

DIAGRAMS

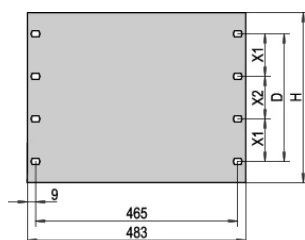

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE