


MTCA.0 System for 6 Single Mid-Size AMC Modules, MTCA.0, 1 U, 84 HP

KATALOGNUMMER

11850-025

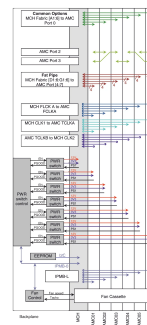

1 U MicroTCA System with horizontal card cage for Single Width AdvancedMC Modules. The chassis has an AC Power input in the rear and an integrated 400 W Power Supply. The PM EMMC (Power Module Enhanced Management Controller) is installed onto the rear of the Backplane.

CERTIFICERINGER



FUNKTIONER

In accordance with PICMG MTCA.0 R1.0 specification

1 U, 19" subrack system for 6 Single Mid-Size AdvancedMC modules, 1 Single Full-Size MCH

AC mains input (100 ... 240 VAC) on rear of case, embedded 400 W PSU, power management (PM EMMC) on backplane

Hot-swap fan module with cooling unit manager (CU EMMC), airflow from right to left

Air filter access from front

PRODUKTEGENSKABER

Product Type: System

Number of Slots: 6

Type: 19" Rack Mount

Backplane Type: MTCA.0 Star Topology, Scope Proposal

Data Transfer: 40 GbE; PCIe Gen3

Power per Slot: 50W

Indgangsspænding AC: 100 – 240V

Airflow Direction: Right to Left

Rack Height: 1U

Power Supply Type: Open Frame

Power Supply Included: Yes

Rear I/O: No

Complies With: PICMG MTCA.0 R2.0

Dybde: 301mm

Højde: 44.45mm

Net Weight: 5.61kg

Pakke mængde: 1

YDERLIGERE PRODUKTOPLYSNINGER

Modified systems available on request.

Completely assembled, wired and tested.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer.

Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE