


Plug-In Unit Microswitch for XL Handle With Cable and Plug

KATALOGNUMMER

20817-877

Micro Switch for XL Front panel.

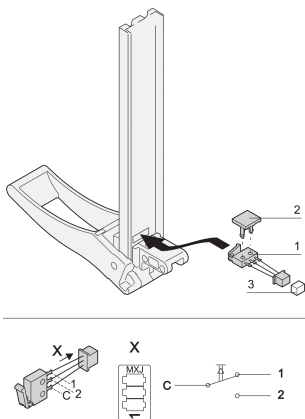

CERTIFICERINGER



FUNKTIONER

Electr. life $\geq 20,000$ switching cycles

Plastic, PC, UL 94 V-0

Molex connector housing

Suitable mating connectors not included in scope of delivery

Mech. life $\geq 20,000$ switching cycles

Operating range $-25\text{ }^{\circ}\text{C}$ to $+70\text{ }^{\circ}\text{C}$

Micro switch for XL handle

Max. switched current 50 mA

Molex crimp contact and fixing clip

PRODUKTEGENSKABER

Product Type: Switch

Works With: Front Panels

Pakke mængde: 10

Dybde: 35.59mm

Gross Weight: 0.012kg

Højde: 8.2mm

Materiale: Polybutylene Terephthalate

Bredde: 7.84mm

YDERLIGERE PRODUKTOPLYSNINGER

Mating connector not included in delivery. Mating connectors from Molex e.g. 53261-0319, 53048-0310, 53047-0310, 53398-0319, 51047-0300.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE