


# VME64x System, 8 U, 21 Slot, Open Frame PSU

## KATALOGNUMMER

**20836-820**

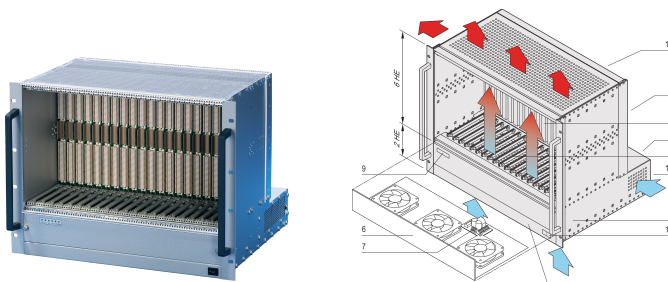

VME64 system for 21 VME64x boards 6 U, 160 mm. Rear I/O option The power for the system is supplied by a open frame power supply. A fan control module monitors the fans, the temperature and voltage.

## CERTIFICERINGER



## FUNKTIONER

System in accordance with IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; backplane conforms to VITA 1.1-1997

PSU, open frame, 642 W (600 W at < 180 VAC)

Backplane VME64x 21 slot, 6 U, J1/J2 monolithic with P0 connector, in accordance with VITA 1-1994 and 1.1-1997

Heat dissipation by 3 fans, cooling from bottom to top; temperature-controlled by fan control module (FCM)

System for standard board mounting with board format, 6 U, 160 mm deep, Rear I / O option

Display module for DC operating voltages, fan and temperature alarm

## PRODUKTEGENSKABER

Product Type: System

Number of Slots: 21

Type: 19" Rack Mount

Backplane Type: 6 U VME64 Extension

Data Transfer: VME64; VME2eSST

Power per Slot: 30W

Indgangsspænding AC: 100 – 240V

Airflow Direction: Bottom to Top

Rack Height: 8U

Power Supply Type: Open Frame

Power Supply Included: Yes

Rear I/O: Yes

Complies With: ANSI/VITA 1.1-1997

Dybde: 412mm

Højde: 354.8mm

Bredde: 449mm

Power: 600W

Net Weight: 19kg

Pakke mængde: 1

## YDERLIGERE PRODUKTOPLYSNINGER

Modified systems available on request.

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**