


Front Handle, for Type R Side Panels

KATALOGNUMMER

24566-010

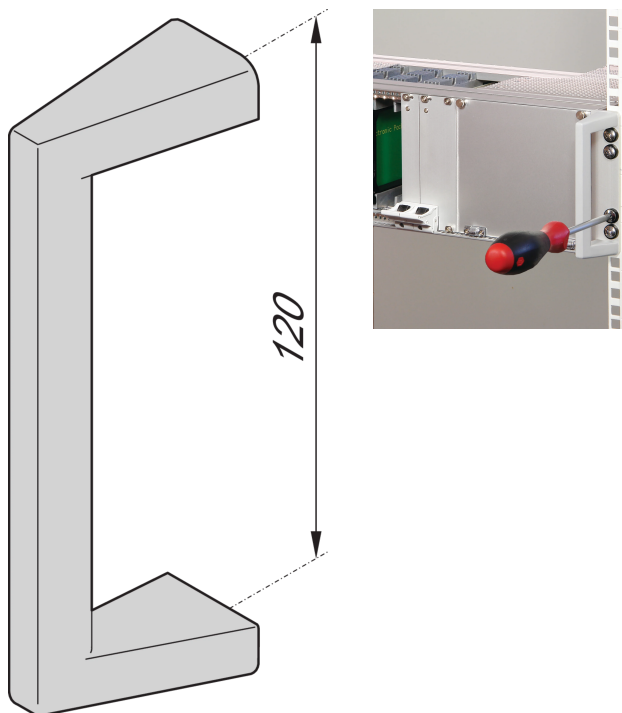

The front handle for a rugged subrack have a load-carrying capacity 30 kg. It optimizes the assembly of a subrack into a cabinet.

CERTIFICERINGER



FUNKTIONER

Load-carrying capacity 30 kg

Suitable for 3 and 6 U side panels

The form of the handle make it much easier to assemble the M6 fixing screws

PRODUKTEGENSKABER

Product Type: Handle

Works With: Subracks

Håndtagstype: Straight

Bredde: 12.2mm

Materiale: Aluminium

Farve: Silver

Pakke mængde: 2

Dybde: 40mm

Finish: Struktur Pulvermaling

Net Weight: 0.154kg

Torque: 2.4N·m

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE