


CPCI System With PSB, 10 U, 14 Slot

KATALOGNUMMER

24579-028

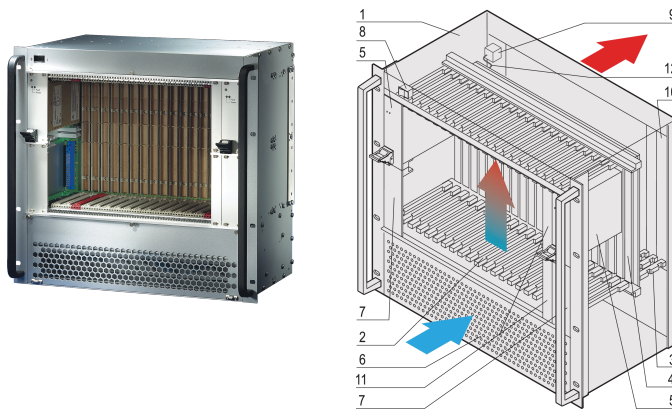

10 U CompactPCI System with PSB for fourteen 6 U Boards, fourteen RTM Boards and up to four 3U pluggable Power Supplies.

CERTIFICERINGER



FUNKTIONER

System in accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11); Backplane, conforms to PICMG 2.16

System with vertical card cage. Board format Front: 6 U, 160 mm deep; Rear I/O: 6 U, 80 mm deep

Backplane, PSB (package switched backplane), PICMG 2.16 16-slot, 6 U, 64 bit (2 fabric/switch slots, 14 node slots)

Heat dissipation by fan module, from front to rear

Two 19" CompactPCI power supplies, 300 W (3 U, 8 HP), prepared for installation of two additional 19" compatible PSUs

Prepared for system monitoring with a chassis monitoring module (CMM)

PRODUKTEGENSKABER

Product Type: System

Number of Slots: 16

Type: 19" Rack Mount

Backplane Type: 6 U CompactPCI with PSB

Data Transfer: 64-bit PCI Bus; GbE

Power per Slot: 40W

Indgangsspænding AC: 100 – 240V

Airflow Direction: Front to Rear

Rack Height: 10U

Power Supply Type: (2) Pluggable AC PSU

Power Supply Included: Yes

Rear I/O: Yes

Complies With: PICMG 2.0 R3.0

Dybde: 275mm

Højde: 443.7mm

Net Weight: 20kg

Pakke mængde: 1

YDERLIGERE PRODUKTOPLYSNINGER

Modified systems available on request.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE