


19" Front Panel, Plain, 3U, 14 HP, 2.5 mm, Al, RAL 7035

KATALOGNUMMER

30118-330

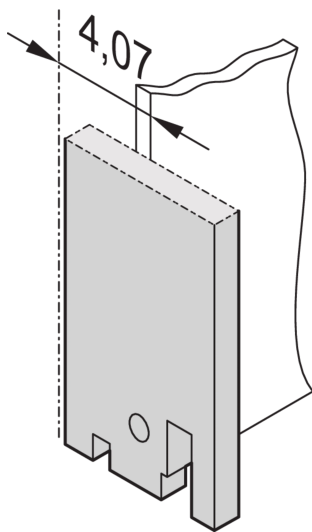

Front panel without or with SUB-D-, ST type 3- or FDDI cut-out.

CERTIFICERINGER



FUNKTIONER

19" Front Panel without Cutout

PRODUKTEGENSKABER

Rack Height: 3U

Rack Width: 14HP

Accessory Type: Front panel

Pakke mængde: 1

Front Finish: Painted

Rear Finish: Conductive

Farvekode: RAL 7035

Dybde: 2.5mm

Finish: Struktur Pulvermaling

Højde: 128.4mm

Materiale: Aluminium

Product Type: Front Panel

Bredde: 70.78mm

Net Weight: 0.06kg

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE