


# Horizontal Rail, Rear, Type R-VT, Rugged, 63 HP

**KATALOGNUMMER**

**34566-763**

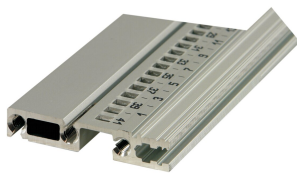

Combinations of horizontal rails and side panels

„+“ can be combined, „-“ combination not recommended

		Light 1.0	Flexibel 1.0	Heavy 1.0	Rugged 1.0
Horizontal rail	Horizontal rail	+	+	+	+
Horizontal rail	Horizontal rail	+	+	+	+
Horizontal rail	Horizontal rail	+	+	-	-
Horizontal rail	Horizontal rail	+	+	-	-

The horizontal rail, type rugged VT enables the direct assembly of a backplane.

**CERTIFICERINGER**



**FUNKTIONER**

Type R-VT "rugged" horizontal rail with 3-hole fixing for increased robustness

Aluminum extrusion, anodized finish, conductive contact surface

**PRODUKTEGENSKABER**

Rack Width: 63HP

Pakke mængde: 1

Finish: Anodized

Length: 325.12mm

Materiale: Aluminium

Produktfamilie: EuropacPRO

Product Type: Horizontal Rail

Type: Rugged, VT

Works With: Subracks

## YDERLIGERE PRODUKTOPLYSNINGER

---

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**