


Tray Handle, Size 2

KATALOGNUMMER

60225-012

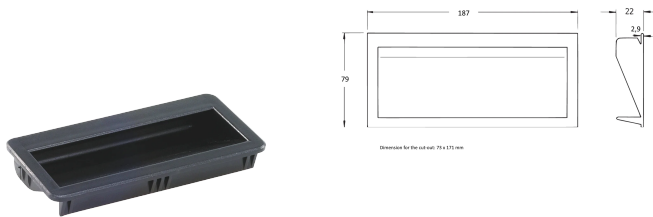

The tray handle can be clip into a cutout in the side panel of a case. 2 sizes available.

CERTIFICERINGER



FUNKTIONER

Static load-carrying capacity 30 kg/pair

Side panel thickness min. 1,0 mm

PRODUKTEGENSKABER

Højde: 79mm

Bredde: 187mm

Dybde: 22mm

Pakke mængde: 1

Håndtagstype: Tray Handle

Flammability Rating: UL® 94V-0

Farve: Black

Materiale: Polycarbonate

Produktfamilie: RatiopacPRO; RatiopacPRO AIR; PropacPRO; CompacPRO; Comptec

Product Type: Handle

Static Load: 30kg

Type: Static

Works With: Cases

Net Weight: 0.064kg

YDERLIGERE PRODUKTOPLYSNINGER

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE