



# Front Panel 1 U, Horizontal Rail Mounting

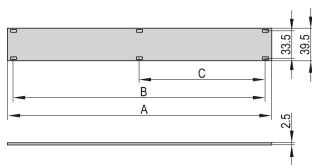

The 1 U front panel enables a user to cover the 1 U section in a 4 U PropacPRO case, RatiopacPRO 5 U (1-3-1) and EuropacPRO 4 U. The panel will be assembled to the threaded inserts of the horizontal rails.

## CERTIFICERINGER

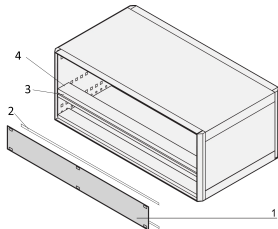

## FUNKTIONER

Mounts on horizontal rails (upper, lower)

## SPECIFIKATIONER

|                        |                                    |
|------------------------|------------------------------------|
| <b>Materiale:</b>      | Aluminium                          |
| <b>Finish:</b>         | Anodized; Passivated               |
| <b>Produktfamilie:</b> | RatiopacPRO; PropacPRO; EuropacPRO |
| <b>Accessory Type:</b> | Front panel                        |
| <b>Product Type:</b>   | Front Panel                        |

Table 1/2


| Katalognummer | Rack Height | Højde (H) | Rack Width | Bredde (W) | Dybde (D) | Pakke mængde |
|---------------|-------------|-----------|------------|------------|-----------|--------------|
| 20850-423     | 1U          | 39.5mm    | 28HP       | 141.9mm    | 2.5mm     | 1            |
| 20850-425     | 1U          | 39.5mm    | 63HP       | 319.7mm    | 2.5mm     | 1            |

| Katalognummer | Rack Height | Højde (H) | Rack Width | Bredde (W) | Dybde (D) | Pakke mængde |
|---------------|-------------|-----------|------------|------------|-----------|--------------|
| 20850-426     | 1U          | 39.5mm    | 84HP       | 426.4mm    | 2.5mm     | 1            |
| 20850-424     | 1U          | 39.5mm    | 42HP       | 213mm      | 2.5mm     | 1            |

Table 2/2

| Katalognummer | Front Finish | Rear Finish | Treated Edges |
|---------------|--------------|-------------|---------------|
| 20850-423     | Anodized     | Conductive  | No            |
| 20850-425     | Anodized     | Conductive  | No            |
| 20850-426     | Anodized     | Conductive  | No            |
| 20850-424     | Anodized     | Conductive  | No            |

## DIAGRAMS

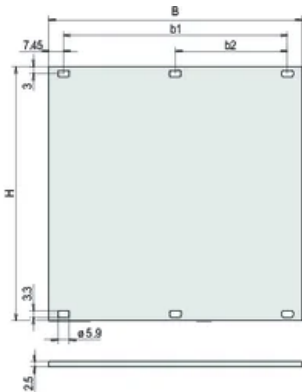

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**