


# Front Panel With AC Input Module

Front Panel for CompactPCI Systems with mounted Wide Range AC Input Module containing AC Plug, Fuse Holder and EMC Filter.

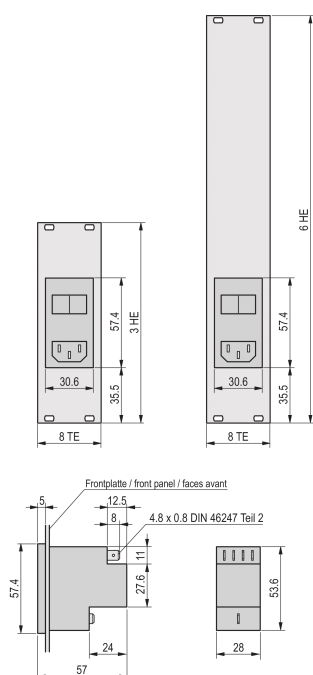

## CERTIFICERINGER



## FUNKTIONER

Voltage 110 VAC ... 250 VAC, 50 Hz ... 60 Hz

Front panel for shielding with EMC textile gasket

Max. current 10 A at 40°C

## SPECIFIKATIONER

**Accessory Type:** Front panel

Table 1/2

| Katalognummer | Materiale | Front Finish | Rear Finish | Rack Height | Højde | Rack Width |
|---------------|-----------|--------------|-------------|-------------|-------|------------|
|---------------|-----------|--------------|-------------|-------------|-------|------------|

|           |           |          |            |    |          |     |
|-----------|-----------|----------|------------|----|----------|-----|
| 24579-059 | Aluminium | Anodized | Anodized   | 3U | 261.75mm | 8HP |
| 24579-058 | Aluminium | Anodized | Conductive | 3U | 128.4mm  | 8HP |

Table 2/2

| Katalognummer | Bredde | Dybde | Pakke mængde | Finish   |
|---------------|--------|-------|--------------|----------|
| 24579-059     | 40.3mm | 2.5mm | 1            | Anodized |
| 24579-058     | 40.3mm | 2.5mm | 1            | Anodized |

## YDERLIGERE PRODUKTOPLYSNINGER

EMC profile seals are required to shield the front panels.

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**