


# Front Panel, Flat, Unshielded, D-Sub Cutouts

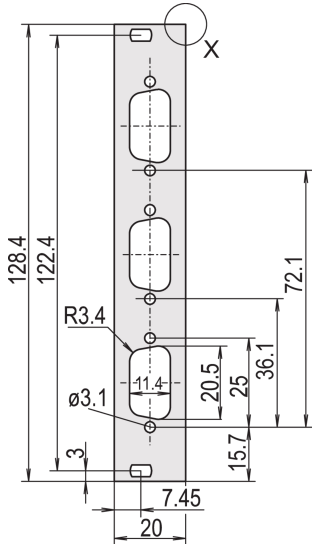

Flat front panel with cutout for D-Sub connectors.  
Unshielded version.

## CERTIFICERINGER



## FUNKTIONER

Non-shielded version

Al, 2.5 mm, front anodized, rear conductive

## SPECIFIKATIONER

<b>Rack Height:</b>	3U
<b>Rack Width:</b>	4HP
<b>Materiale:</b>	Aluminium
<b>Finish:</b>	Anodized; Passivated
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel
<b>Type:</b>	Front Panel without Handle

Table 1/2

Katalognummer	Pakke mængde	Mounting	Front Finish	Rear Finish	Number of Pins	Treated Edges
30118-343	1	Screw-on Front	Anodized	Conductive	(1) 25	No
30118-345	1	Screw-on Front	Anodized	Conductive	(2) 15	No
30118-344	1	Screw-on Front	Anodized	Conductive	(2) 9	No
30118-346	1	Screw-on Front	Anodized	Conductive	(2) 25	No
30118-347	1	Screw-on Front	Anodized	Conductive	(3) 9	No
30118-342	1	Screw-on Front	Anodized	Conductive	(1) 15	No
30118-341	1	Screw-on Front	Anodized	Conductive	(3) 9	No

Table 2/2









Katalognummer	Complies With	Dybde (D)	EMC Shielding	Højde (H)	Bredde (W)
30118-343	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm
30118-345	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm
30118-344	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm
30118-346	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm
30118-347	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm
30118-342	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm
30118-341	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm

## YDERLIGERE PRODUKTOPLYSNINGER

Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

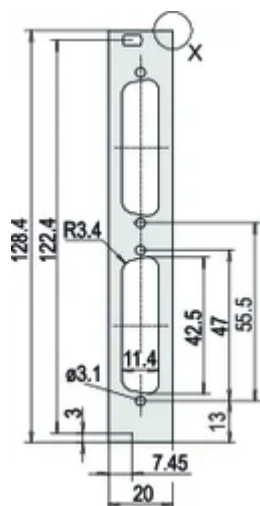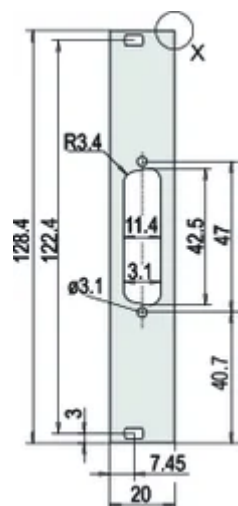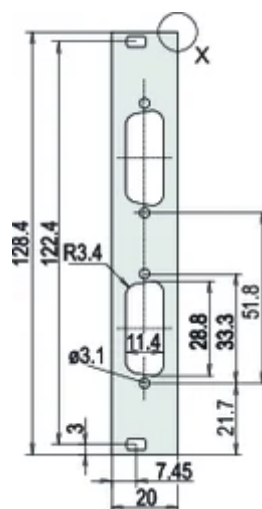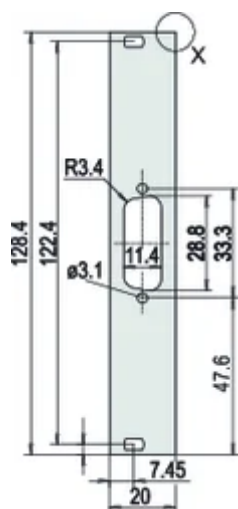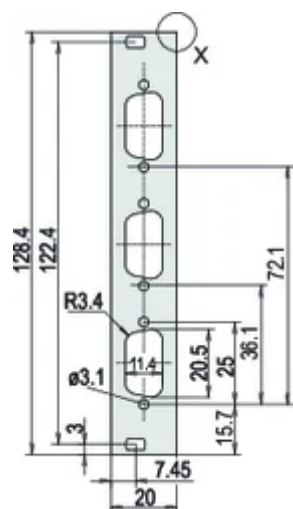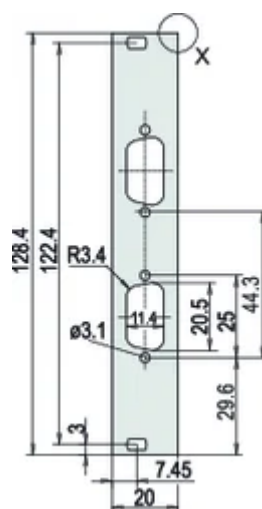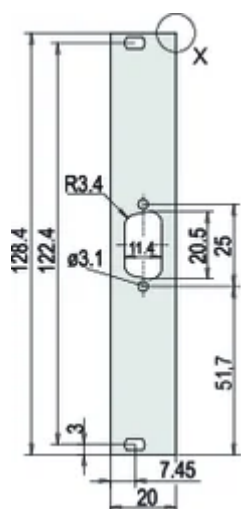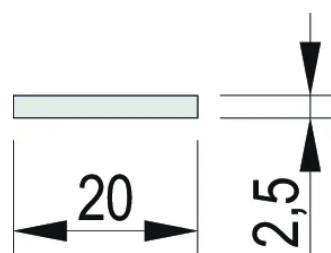

**ADVARSEL**

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**