

# Front Panel, Unshielded, Bottom Hinged

Unshielded front panel bottom hinged.



## CERTIFICERINGER



## FUNKTIONER

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

## SPECIFIKATIONER

|                        |                            |
|------------------------|----------------------------|
| <b>Dybde (D):</b>      | 2.5mm                      |
| <b>Materiale:</b>      | Aluminium                  |
| <b>Finish:</b>         | Anodized                   |
| <b>Accessory Type:</b> | Front panel                |
| <b>Product Type:</b>   | Front Panel                |
| <b>Type:</b>           | Front Panel without Handle |

Table 1/2

| Katalognummer | Rack Height | Rack Width | Pakke mængde | Mounting       | Front Finish | Rear Finish |
|---------------|-------------|------------|--------------|----------------|--------------|-------------|
| 20838-280     | 3U          | 28HP       | 1            | Hinged, Bottom | Anodized     | Conductive  |
| 20838-271     | 3U          | 42HP       | 1            | Hinged, Bottom | Anodized     | Conductive  |
| 20838-274     | 6U          | 42HP       | 1            | Hinged, Bottom | Anodized     | Conductive  |
| 20838-279     | 4U          | 84HP       | 1            | Hinged, Bottom | Anodized     | Conductive  |

| Katalognummer | Rack Height | Rack Width | Pakke mængde | Mounting       | Front Finish | Rear Finish |
|---------------|-------------|------------|--------------|----------------|--------------|-------------|
| 20838-272     | 3U          | 63HP       | 1            | Hinged, Bottom | Anodized     | Conductive  |
| 20838-275     | 6U          | 63HP       | 1            | Hinged, Bottom | Anodized     | Conductive  |
| 20838-278     | 4U          | 63HP       | 1            | Hinged, Bottom | Anodized     | Conductive  |
| 20838-277     | 4U          | 42HP       | 1            | Hinged, Bottom | Anodized     | Conductive  |
| 20838-276     | 6U          | 84HP       | 1            | Hinged, Bottom | Anodized     | Conductive  |
| 20838-273     | 3U          | 84HP       | 1            | Hinged, Bottom | Anodized     | Conductive  |


Table 2/2

| Katalognummer | Treated Edges | Complies With                      | EMC Shielding | Højde (H) | Bredde (W) |
|---------------|---------------|------------------------------------|---------------|-----------|------------|
| 20838-280     | No            | IEC 60297-3-101,<br>IEEE 1101.1/10 | No            | 128.4mm   | 141.9mm    |
| 20838-271     | No            | IEC 60297-3-101,<br>IEEE 1101.1/10 | No            | 128.4mm   | 213mm      |
| 20838-274     | No            | IEC 60297-3-101,<br>IEEE 1101.1/10 | No            | 261.8mm   | 213mm      |
| 20838-279     | No            | IEC 60297-3-101,<br>IEEE 1101.1/10 | No            | 172.9mm   | 426.4mm    |
| 20838-272     | No            | IEC 60297-3-101,<br>IEEE 1101.1/10 | No            | 128.4mm   | 319.7mm    |
| 20838-275     | No            | IEC 60297-3-101,<br>IEEE 1101.1/10 | No            | 261.8mm   | 319.7mm    |
| 20838-278     | No            | IEC 60297-3-101,<br>IEEE 1101.1/10 | No            | 172.9mm   | 319.7mm    |
| 20838-277     | No            | IEC 60297-3-101,<br>IEEE 1101.1/10 | No            | 172.9mm   | 213mm      |
| 20838-276     | No            | IEC 60297-3-101,<br>IEEE 1101.1/10 | No            | 261.8mm   | 426.4mm    |
| 20838-273     | No            | IEC 60297-3-101,<br>IEEE 1101.1/10 | No            | 128.4mm   | 426.4mm    |

## YDERLIGERE PRODUKTOPLYSNINGER

Front panel can be removed in opened position (> 135°).

## DIAGRAMS

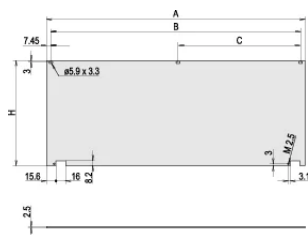

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**