


Inpac Front Panel

The front panel can be assembled on to the Inpac Case.

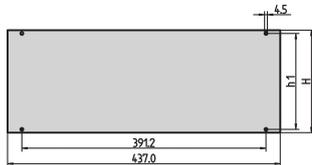

CERTIFICERINGER



FUNKTIONER

Al panel, 2.5 mm

SPECIFIKATIONER

Dybde:	2.5mm
Materiale:	Aluminium
Finish:	Anodized
Works With:	Cases
Accessory Type:	Front panel
Product Type:	Front Panel
Produktfamilie:	Inpac

Table 1/2

Katalognummer	Rack Height	Pakke mængde	Front Finish	Rear Finish	Treated Edges	EMC Shielding
30828-055	2U	1	Anodized	Anodized	No	No
30828-067	6U	1	Anodized	Anodized	No	No
30828-061	4U	1	Anodized	Anodized	No	No
30828-058	3U	1	Anodized	Anodized	No	No

Table 2/2

Katalognummer	Højde	Bredde
30828-055	76mm	437mm
30828-067	253.8mm	437mm
30828-061	165mm	437mm
30828-058	120.5mm	437mm

YDERLIGERE PRODUKTOPLYSNINGER

The assembly kit for the front panel is included with the 19" chassis.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE