


# Plastic Foot

Tip-up feet, Plastic.

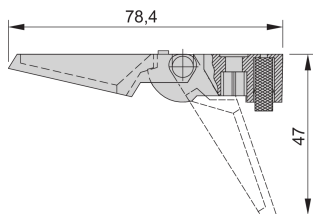

## CERTIFICERINGER



## FUNKTIONER

Can be used instead of standard round feet

Load-carrying capacity: 25 kg per foot, max case weight 40 kg

Mounting holes are provided in bottom covers of the cases

Positioning of case is secured by anti-slip rubber inserts

## SPECIFIKATIONER

|                        |                                                           |
|------------------------|-----------------------------------------------------------|
| <b>Works With:</b>     | Cases                                                     |
| <b>Produktfamilie:</b> | RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac |
| <b>Type:</b>           | Foot; With Tip-up                                         |
| <b>Product Type:</b>   | Foot                                                      |
| <b>Materiale:</b>      | Polyamide                                                 |

Table 1/1

| Katalognummer | Pakke mængde |
|---------------|--------------|
| 10603-023     | 1            |
| 10603-026     | 1            |
| 10603-025     | 1            |
| 10603-024     | 1            |

## YDERLIGERE PRODUKTOPLYSNINGER

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**