


Test Adaptor for VMEbus

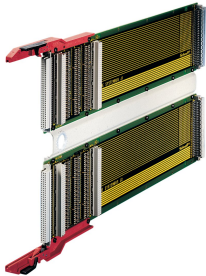

Test Adaptor for VMEbus Boards to access test points on the board.

CERTIFICERINGER



FUNKTIONER

Routing and layer stack-up match the requirements of the VME bus

Measuring field for current and voltage measurement (V/I), (a)

Additional measuring pins, e.g. for the probe tips of an oscilloscope (b)

1 pin position for second test object, 1 pin position for terminator board

6 U test adaptors consist of two 3 U test adaptors linked via an intermediate adaptor

Voltage supply lines are designed for 2 A

SPECIFIKATIONER

Table 1/2

Katalognummer	Type	Connector Type	Board Depth	Rack Height	Measuring Field	Number of Layers
23022-010	VMEbus	C96, System Bus, C96, I/O Bus	280mm	6U	Current, Voltage	6
23021-100	VMEbus	C96, I/O Bus	160mm	3U	Current, Voltage	6
23021-002	VMEbus	C96, System Bus	220mm	3U	Current, Voltage	6

Katalognummer	Type	Connector Type	Board Depth	Rack Height	Measuring Field	Number of Layers
23022-004	VMEbus	C96, System Bus, C96, I/O Bus	220mm	6U	Current, Voltage	6
23021-001	VMEbus	C96, System Bus	160mm	3U	Current, Voltage	6
23022-002	VMEbus	C96, System Bus, C96, I/O Bus	160mm	6U	Current, Voltage	6
23021-101	VMEbus	C96, I/O Bus	220mm	3U	Current, Voltage	6

Table 2/2

Katalognummer	Pakke mængde
23022-010	1
23021-100	1
23021-002	1
23022-004	1
23021-001	1
23022-002	1
23021-101	1

YDERLIGERE PRODUKTOPLYSNINGER

For 9 U VMEbus test Adapter solution see Intermediate Adaptor Adaptor Bracket, 9 U, 220 mm, 350 mm.

P1 = System Bus, P2 = I/O Bus.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE