


Frontplatten-Satz, ungeschirmt, untere Scharniere, 6 HE, 84 TE, 2,5 mm, Al, eloxiert

KATALOGNUMMER

20838-276

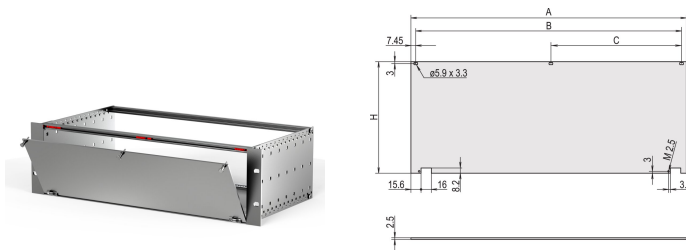

Ungeschirmte Frontplatte mit klappbarem Scharnier.

ZERTIFIZIERUNGEN



MERKMALE

Frontplatte beim Aufklappen bei 135° aushängbar (nicht bei RatiopacPRO)

Die Montage erfolgt an den Modulschienen

PRODUKTMERKMALE

Höhe Gestell: 6U

Zubehörtyp: Frontplatte

Breite Gestell: 84HP

Anzahl Verpackungen: 1

Befestigung: Mit Scharnier, unten

Frontbeschichtung: Eloxier

Oberfläche Rückseite: Leitend

Behandelte Kanten: Nein

Tiefe (D): 2.5mm

Oberfläche: Eloxiert

Material: Aluminium

Typ: Frontplatte ohne Griff

Net Weight: 0.93kg

Frontplatte lässt sich im aufgeklappten Zustand ($> 135^\circ$) aushängen.

Technical drawing of a rectangular plate. The drawing shows a rectangle with various dimensions and labels. The top edge is labeled with dimensions 7.45, A, B, and C. The left edge is labeled with dimensions 3, H, and 15.6. The bottom edge is labeled with dimensions 16, 8.2, 3, and 2.5. The right edge is labeled with dimensions 42.5 and 3. A small circle with the text "ø5.9 x 3.3" is located near the top-left corner. A small square with the text "42.5" is located near the bottom-right corner.

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Unser starkes markenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE