

# Hex Head Bolt

## FEATURES

Fully threaded hexagon head bolt

## SPECIFICATIONS


**Complies With:** DIN 933

**Material:** Steel

Table 1/1

Catalog Number	Article Number	Finish	Screw Diameter (Sc)	Screw Length (L)
HSCRM1025HD	593745	Hot-Dip Galvanized	10	25mm
HSCRM825EG	593680	Electrogalvanized	8	25mm
HSCRM1030HD	593755	Hot-Dip Galvanized	10	30mm
HSCRM1230HD	593765	Hot-Dip Galvanized	12	30mm

## DIAGRAMS

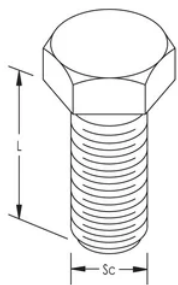

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

**Europe**

Netherlands:

+31 800-0200135

France:

+33 800 901 793

**Europe**

Germany:

800 1890272

Other Countries:

+31 13 5835404

**APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

