

# nVent CADDY Cat CM U-Hook, Strut Mount, 203 mm

## Data Solutions

### CATALOG NUMBER

---

**CAT200CM**



### CERTIFICATIONS

---



### FEATURES

---

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Integrated quick-attach T-nut allows U-Hooks to be quickly mounted to strut

System offers a convenient pathway for wires and cables

Specially designed U-Hooks have large-diameter, rounded support surfaces

Rounded edges help prevent over-bending and kinking of cables

Ideal for retrofit applications where cable runs need to be routed around existing building infrastructure

Compliant with NEC® and ANSI®/TIA structured cabling systems standards

### PRODUCT ATTRIBUTES

---

Article Number: 181982

Material: Steel

Finish: Electrogalvanized

Included Components: Quick-Attach T-Nut

Cable Capacity, Cat 5e: 450

Cable Capacity, Cat 6: 350

Cable Capacity, Cat 6A: 215


A: 203mm

Area: 533mm<sup>2</sup>

Hole Size (HS): 9.5mm

Static Load: 440N

## DIAGRAMS

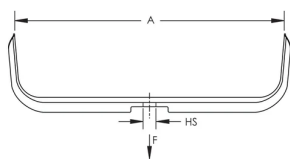

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**