


# Joint Bond T6 Complete Welder Pair, Signal, 1" Tab Bond Terminal Style, 35 mm<sup>2</sup> Ropelay

## Data Solutions

### CATALOG NUMBER

**SBST6X2**

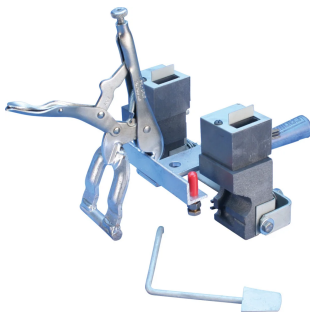

### FEATURES

- Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail, across the joint
- Connection is made within the confines of the splice bar
- Includes mold cleaner

### PRODUCT ATTRIBUTES

- Article Number: 222628
- Material: Steel; Graphite; Thermoplastic
- Rail Type: 85 lb to 141 lb T-Rail Sections
- Bond Terminal Style: 1" Tab
- Conductor Size: 35 mm<sup>2</sup> Ropelay
- Conductor Outer Diameter, Nominal: 7.75mm
- Bond Length: 177.8mm
- Welder Style: T6
- Mold Only: No
- Replacement Mold: SBSX2

Welding Material: SB25 x 2, Sold Separately

Frame: SBSX2F, Sold Separately

Bond Clip: SBS119 x 2, Sold Separately

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**