


Varistar CP Cabinet Frame, 47 U, 2200H, 600W, 1000D

Data Solutions

CATALOG NUMBER

20630-114

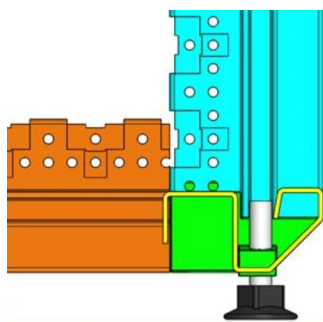

Varistar CP welded frame is available for static load requirements and can be integrated with 19", ETSI or mounting plate. Additionally, castors can be added to the frame if needed.

However, if you require castors for your application, you might want to consider a mobile frame that already includes castors.

FEATURES

Welded, finish powder-coated, black gray, RAL 7021

St, 1.5 mm, zinc-plated, with central GND/grounding point

Static load-carrying capacity max. 1600 kg

Please order adjustable feet separately

PRODUCT ATTRIBUTES

Rack Height: 47U
Height: 2200mm
Width: 600mm
Depth: 1000mm
Package Quantity: 1
Color: Black Grey
Color Code: RAL 7021
Complies With: IEC 61587-1; IEC 61587-3
Frame Material: Steel
Material: Steel
Product Family: Varistar CP
Product Type: Cabinet/Rack Frame
Static Load: 1600kg
Type: Standard
Works With: Varistar CP
Net Weight: 40.678kg

ADDITIONAL PRODUCT DETAILS

Castor can be added to the frame. If you will need a castor for your application, you can order a mobile frame which include castors.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE