

nVent CADDY Cat CM U-Hook, Strut Mount, 304 mm

Data Solutions

CATALOG NUMBER

CAT300CM



CERTIFICATIONS



FEATURES

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Integrated quick-attach T-nut allows U-Hooks to be quickly mounted to strut

System offers a convenient pathway for wires and cables

Specially designed U-Hooks have large-diameter, rounded support surfaces

Rounded edges help prevent over-bending and kinking of cables

Ideal for retrofit applications where cable runs need to be routed around existing building infrastructure

Compliant with NEC® and ANSI®/TIA structured cabling systems standards

PRODUCT ATTRIBUTES

Article Number: 181984

Material: Steel

Finish: Electrogalvanized

Included Components: Quick-Attach T-Nut

Cable Capacity, Cat 5e: 700

Cable Capacity, Cat 6: 525

Cable Capacity, Cat 6A: 325


A: 304mm

Area: 812mm²

Hole Size (HS): 9.5mm

Static Load: 440N

DIAGRAMS

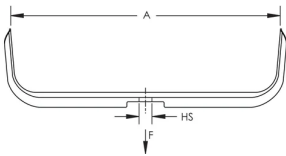

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE