

ATCA Front Panel Kit With Spring Loading



AdvancedTCA front panel for spring-loaded IEA handle (plunger or lever style) with die-cast end piece in Al-Profile or stainless material.

CERTIFICATIONS



FEATURES

Front panel (reinforced with diecast endpiece)

ATCA IEA handle with spring loading

EMC textile gasket and fixing material

SPECIFICATIONS

Rack Width:	6HP
Rack Height:	8U
Accessory Type:	Front panel
Product Type:	Front Panel


Table 1/2

Catalog Number	Material	Finish	Package Quantity	Front Finish	Rear Finish	Depth (D)
20818-160	Stainless Steel		1	Raw	Raw	1mm
20818-169	Aluminum	Passivated	1	Raw	Raw	1mm
20818-161	Stainless Steel		1	Raw	Raw	1mm
20818-170	Aluminum	Passivated	1	Raw	Raw	1mm

Table 2/2

Catalog Number	Height (H)	Width (W)
20818-160	323.15mm	28.95mm
20818-169	323.15mm	28.95mm
20818-161	323.15mm	28.95mm
20818-170	323.15mm	28.95mm

DIAGRAMS

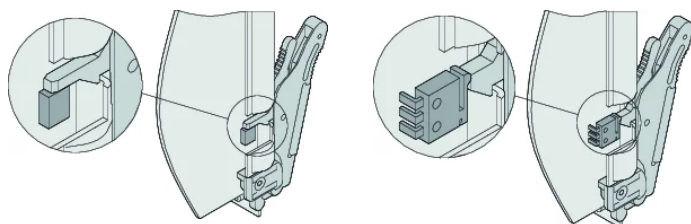

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE