


# Countersunk Screw

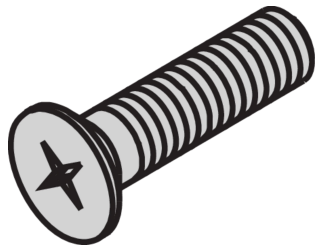

Countersunk screws are used for numerous mounting options in a subrack or desktop case.

## CERTIFICATIONS



## FEATURES

Countersunk screw

## SPECIFICATIONS

**Product Type:** Screw

Table 1/2

Catalog Number	Length	Material	Finish	Package Quantity	Thread Size	Height
24560-139	5mm	Steel	Zinc Plated	100	M4	
24560-183	12mm	Steel	Zinc Plated	100	M5	
24560-182	12mm	Steel	Zinc Plated	4	M5	
24560-145	14mm	Steel	Zinc Plated	100	M4	
24560-164	8mm	Steel	Nickel Plated	100	M2.5	4.7mm
24560-158	7.7mm	Steel	Zinc Plated	100	M2.5	
21100-542	8mm	Steel	Nickel Plated	100	M3	
21100-429	8mm	Steel	Nickel Plated	100	M2.5	
21100-649	10mm	Steel	Zinc Plated	100	M2.5	

Catalog Number	Length	Material	Finish	Package Quantity	Thread Size	Height
21100-500	10mm	Steel	Nickel Plated	100	M2.5	
21100-507	12mm	Steel	Nickel Plated	100	M2.5	

Table 2/2

Catalog Number	Type	Width	Works With	Thread Type	Torque
24560-139	Countersunk Screw		Front Panels		1.3N·m
24560-183	Countersunk Screw		Front Panels		2.4N·m
24560-182	Countersunk Screw		Front Panels		2.4N·m
24560-145	Countersunk Screw		Front Panels		2.4N·m
24560-164	Countersunk Screw	4.7mm	Front Panels	Metric	
24560-158	Countersunk Screw		Front Panels		
21100-542	Screw		Front Panels		
21100-429	Screw		Front Panels		
21100-649	Screw		Front Panels		
21100-500	Screw		Front Panels		
21100-507	Screw		Front Panels		

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**