


# Frame-Reducing Brackets for Frames or Mounting Channel

## Data Solutions

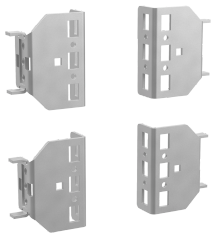

The Frame-reducing Brackets mount directly to 700-mm or 800-mm wide ProLine frames or to mounting channel. They convert wider frames to 600-mm wide, allowing 19-in. rack angles to fit, or to 700-mm wide, allowing 23-in. rack angles to fit. They can be used to left- or right-justify the rack-mounted equipment. Please note they are furnished in sets of four and mounting hardware is included.

### FEATURES

The Frame-reducing Brackets mount directly to 700-mm or 800-mm wide ProLine frames or to mounting channel

They convert wider frames to 600-mm wide, allowing 19-in. rack angles to fit, or to 700-mm wide, allowing 23-in. rack angles to fit

They can be used to left- or right-justify the rack-mounted equipment

Furnished in sets of four with mounting hardware included

### SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Color	Color Code	Thickness
PMURB50	11268	Mild Steel	Powder Coated	Jet Black	RAL 9005	1.9mm
PMURB100	11263	Mild Steel	Powder Coated	Jet Black	RAL 9005	1.9mm

Table 2/2

Catalog Number	Article Number	Reduces Frame Width	Converts Frame Width
PMURB50	11268	50mm	From 700 mm to 600 mm, From 800 mm to 700 mm

Catalog Number	Article Number	Reduces Frame Width	Converts Frame Width
PMURB100	11263	100mm	From 800 mm to 600 mm, From 800 mm to 700 mm, From 700 mm to 600 mm

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**