

# Push-In Insert for Sheet Metal



## FEATURES

For installation of plastic conduit clamps and clips on cable trays or spring steel fasteners with holes

Passed 650°C glowing/hot-wire wire test per EN 60695-2

Halogen free

UV-stabilized

## SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Temperature	Height (H)	Width (W)	Thickness (T)
SCESV	800034	Nylon	-20 to 85 °C	18 mm	20 mm	0.50 - 1.1 mm

Table 2/2

Catalog Number	Article Number	Hole Size (HS)
SCESV	800034	6 - 8 mm

## DIAGRAMS

---

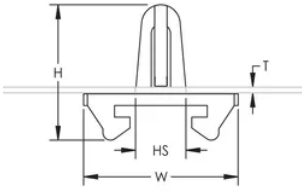

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

