


# Door-Mount PDU 4.3-inch LCD Display, 5.24x3.54x0.67, Black, Plastic

## Data Solutions

### CATALOG NUMBER

### LCD4INDRMT

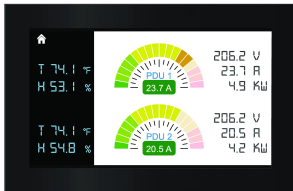

Smart, stylish Door-Mount PDU LCD Display externally monitors the PDU metrics inside the cabinet without opening the door to physically review the PDU's metrics. Easy magnetic mounting installation not requiring any cabinet door cutout. Touchscreen can be installed horizontally or vertically and has plug-n-play connectivity.

### FEATURES

Saves time monitoring PDU metrics from outside the cabinet

Prevents entering cabinet to monitor PDU metrics

Easy magnetic mounting installation

No cabinet door cutout required

Optional mounting screw kit included

Display horizontally or vertically

Plug-n-Play connectivity

Resistive touch screen

Smart and stylish design

With corresponding PDU connected sensors, it monitors voltage, current, power, temperature, humidity and air flow

4.3-inch (109mm) display size

480 x 272 display resolution

RJ-11 cables connection

## PRODUCT ATTRIBUTES

---

Article Number: 39385

Height: 133mm

Width: 90mm

Depth: 17mm

Material: Plastic

Color: Black

Display: LCD

Resolution: 480 x 272

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**