

# CAPB Cap Nut with Threaded Stud



## CERTIFICATIONS



## FEATURES

For use with DH Distance Holder and Spacer

## SPECIFICATIONS


- Temperature:** 80 °C Max
- Finish:** Electrogalvanized
- Material:** Steel;Polystyrene
- Flammability Rating:** UL® 94HB

Table 1/1

Catalog Number	Article Number	Thread Size (TS)	Thread Length (TL)	Height (H)	Width (W)	Unit Weight
CAP-CAPB6	560850	M6	8mm	12 mm	14 mm	0 kg
CAP-CAPB5	560840	M5	8mm	12 mm	14 mm	0 kg

## DIAGRAMS

---

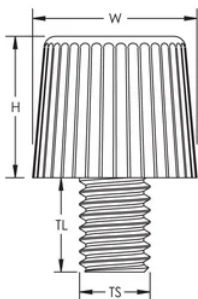

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**