


# PropacPRO Case Design Elements

To individualize the PropacPRO case design. The elements will be screwed from the rear side of the die cast frame.

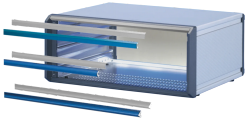

## CERTIFICATIONS



## FEATURES

To individualize the case design

Available in 3 forms and two colors

## SPECIFICATIONS

- Material:** Aluminum
- Finish:** Anodized
- Works With:** Cases
- Product Type:** Corner Profile
- Product Family:** PropacPRO

Table 1/1

| Catalog Number | Rack Width | Type     | Color Code | Color          |
|----------------|------------|----------|------------|----------------|
| 20850-299      | 42HP       | Rounded  | RAL 5007   | Brilliant Blue |
| 20850-196      | 42HP       | Triangle | RAL 7035   | Light Grey     |
| 20850-190      | 42HP       | Squared  | RAL 7035   | Light Grey     |
| 20850-315      | 42HP       | Squared  | RAL 5007   | Brilliant Blue |

| Catalog Number | Rack Width | Type     | Color Code | Color          |
|----------------|------------|----------|------------|----------------|
| 20850-184      | 42HP       | Rounded  | RAL 7035   | Light Grey     |
| 20850-331      | 42HP       | Triangle | RAL 5007   | Brilliant Blue |
| 20850-185      | 63HP       | Rounded  | RAL 7035   | Light Grey     |
| 20850-191      | 63HP       | Squared  | RAL 7035   | Light Grey     |
| 20850-197      | 63HP       | Triangle | RAL 7035   | Light Grey     |
| 20850-316      | 63HP       | Squared  | RAL 5007   | Brilliant Blue |
| 20850-332      | 63HP       | Triangle | RAL 5007   | Brilliant Blue |
| 20850-300      | 63HP       | Rounded  | RAL 5007   | Brilliant Blue |
| 20850-192      | 84HP       | Squared  | RAL 7035   | Light Grey     |
| 20850-198      | 84HP       | Triangle | RAL 7035   | Light Grey     |
| 20850-186      | 84HP       | Rounded  | RAL 7035   | Light Grey     |
| 20850-317      | 84HP       | Squared  | RAL 5007   | Brilliant Blue |
| 20850-333      | 84HP       | Triangle | RAL 5007   | Brilliant Blue |
| 20850-301      | 84HP       | Rounded  | RAL 5007   | Brilliant Blue |

## ADDITIONAL PRODUCT DETAILS

---

Size 28 HP and further colors available on request.

Cannot be combined with front hood.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**